



EMPTY ENCLOSURE

# TK PC 75-4-o



## TK PC 75-4-o


Empty enclosure

**CUSTOMIZABLE**

65 x 50 x 35 mm  
Article number: 12047501

Empty enclosure - Industrial Quality, Base and cover: glass fibre reinforced polycarbonate, Grey, similar to RAL 7035

without pre-embossings

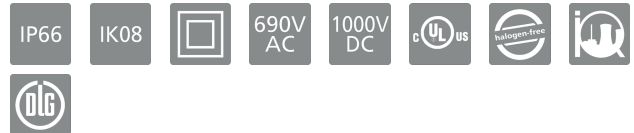

## Technical data

### Measures

Width:	65 mm
Length:	50 mm
Height:	35 mm
Inner height:	24 mm

### Material

Base:	Polycarbonate, glass fibre reinforced, grey similar to RAL 7035
Cover:	Polycarbonate, glass fibre reinforced, grey similar to RAL 7035
Sealing:	Polyurethane
Cover screw:	stainless steel V2A

## Accessory

TK MPI-75 - Mounting plate

TK ABP-55/75 - External fixing plate

TK ES-55/75/1005 - Installation screw

TK MLH-55/75 - Mounting / PCB holder

## Environmental attributes

Ambient temperature (min.):	-35 °C
Ambient temperature (max.):	80 °C
Ambient temperature (24 h):	60 °C
Max. rel. humidity at 25° C (short term):	95%
Max. rel. humidity at 40° C:	50%



EMPTY ENCLOSURE

# TK PC 75-4-o

## Other attributes

Ingress protection:	IP66 - acc. EN 60529 / DIN VDE 0470-1
Impact resistance:	IK08 acc. DIN EN 5012 / VDE 0470 segment 100
Protection class:	II - isolate protection acc. VDE 0106
Rated insulation voltage AC:	690 V
Rated insulation voltage DC:	1000 V
Heavy metals-free:	Yes
PVC-free:	Yes
Silicone-free:	Yes
Fitted for outdoor application:	Yes
Combustion behaviour to UL 50 / UL 746C:	5VA nach UL 50 / UL 746C
Combustion behaviour acc. to UL 94:	V-2 acc. UL 94
Combustion behaviour acc. to VDE:	960°C acc. VDE 0471/ EN 60695
Weatherproof:	Yes
Cable entries:	No