

BRIEF INTRODUCTION

TAISHAN

Model No.: D03K

D03K is a digital audio analog convertor, which can transfer digital audio (optical/coaxial) to two channels analog audio and amplify the output (but using directly on headphone is not recommended), just suitable for using together with the devices such as digital television, CD/DVD/Blue-ray player etc., which with coaxial or optical digital signal output.

Feature and main function:

- Maximum support 192KHz/24bit audio signal
- Optical/coaxial optional input function
- 2 sound channels stereo RCA audio output
- 3.5mm sound output dock
- Indication for digital receiving status (LOCKED)
- MINI USB power supply port
- Support form is PCM, donnot support DOLBY and DTS form

List of items in the package (please verify)

D03K 1PCS; Power adaptor 1PCS; User manual 1PCS

Specifications:


- | | |
|----------------------------|--------------------|
| ●Power supply | DC 5V |
| ●Output amplitude | 1.5V (0dB Fs) |
| ●Frequency Response | 20Hz~20KHz |
| ●Signal to Noise Ratio | ≥95dB |
| ●Crosstalk | ≥85dB |
| ●Total harmonic distortion | <0.008% |
| ●Size | 61.6mm×49.1mm×21mm |
| ●Weight | 50g |

INSTRUCTIONS FOR USE

**Analog audio signal RCA
L/R output port**



**Optical input port:
connect to player**

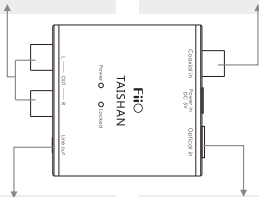

Line output connector:
Connect wireless audio
transmitter



**Digital signal coaxial input
port: Digital TV**



INSTRUCTIONS FOR USE

Power indicator :


when power on, red light is on; power off, the light off.

Indicated light for signal status:

Blue light on when receiving valid data

USB power supply input: DC5V

Coaxial/Optical switch: with to relative place according to input sound source

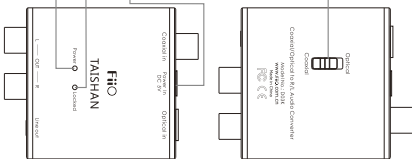

FQA

- No sound output or sound with noisy, please set digital output of sound source to be PCM form or insert the power and try it again. (Donnot support DOLBY and DTS digital audio)
- Music input connector might have a faulty or unsuitable connection, please reconnect the plug
- Please use the include stock cable or a compatible frequency connect cable in order to ensure a secured output

IMPORTANT NOTE

- ★Do not try to open , repair the device and place it near a source of liquid
- ★Please see to it that original power supply are required, or high quality power supply with voltage range with 5V \equiv 200mA, with out warranty when the device be damaged by the third party using unsuitable power supply

SPECIAL STATEMENT

- ★Our company has the final interpretation of this instruction, if any discrepancy found between the description of user manual and product, please refer to actual product.
- ★Our company reserve the right to amend the technical rules without prior notice.
- ★Our company reserve the right to amend this instruction without any further notice.
- ★The manufacturer retains the right to modify the product without advance notice.

CONTACT INFORMATION

FiiO[®]

FiiO Electronic Technology Ltd.

Tel: +86-20-62679040 Fax: +86-20-62679042

Address: 2/F, F Building, Hougang Industrial Zone, Shigang Village,
Huangshi West Road, Baiyun District, Guangzhou, China.

[http:// www.fiiocom.cn](http://www.fiiocom.cn) Postcode : 510430

The machine cannot work normally or any other questions:
please visit our website (<http://www.fiiocom.cn/support/>)
to post comments or send email to market@fiiocom.cn.

Qualified Certificate

V00

DATE:
(D-M-Y)

FC CE 5190104

Manufactured by FiiO

Made in China