


## PA80F/F

Interlocking barrier terminal block pa81 end plate for modular pa80

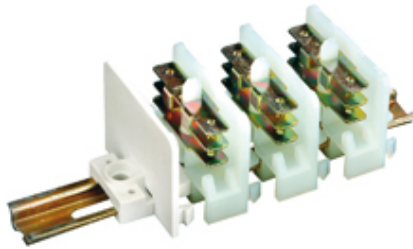

### SPECIFICATION

Tab Size (mm)	6.3x0.8
Terminal Material	Zinc-plated steel
Body Material	Natural polyamide
UL94 Rating	UL94V2
Max Conductor Size (Sq mm)	2.5
Min Conductor Size AWG	22
Max Conductor Size AWG	12
Max Current (A)	20
Max Voltage (V)	450
Minimum Temp Rating °C	-5
Max Temp Rating °C	110
Height (mm)	29
Width (mm)	38
Length (mm)	11
Accessories Available	PA262 ACC

### DISTRIBUTORS

