


The supplier acknowledges that, with the acceptance of the drawing, he is in a position to manufacture the illustrated part in accordance with the drawing in reproducible form and series production. Through the selected manufacturing processes no impairments will arise in the material and structure which could subsequently lead to an impairment of the component. Verbal agreements over and above that are not valid. Deviations from this rule must be written and must be signed by the purchaser.

This drawing may not be copied, reproduced or made available to third parties in any way whatsoever without or prior written approval.

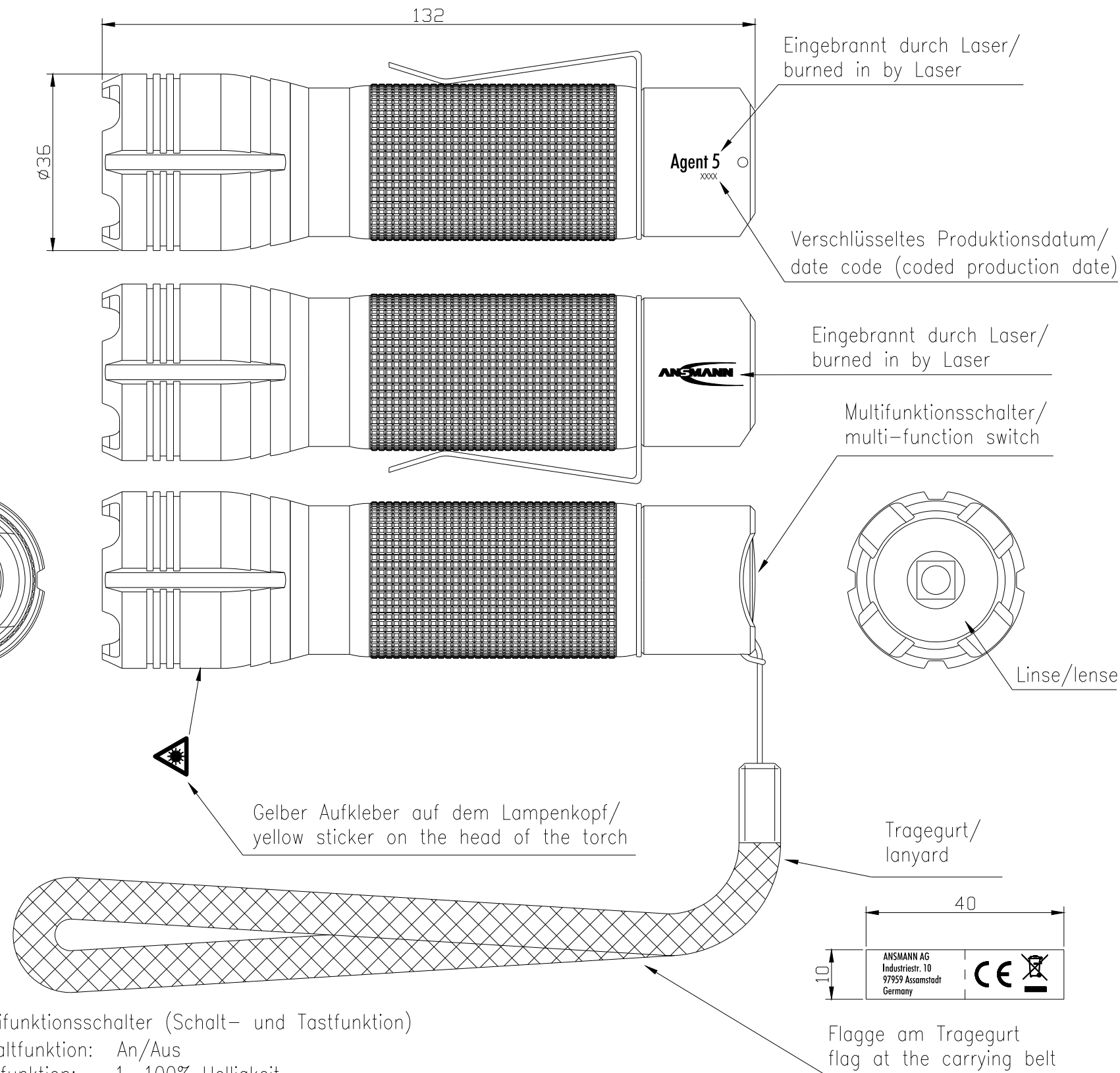

- Technische Daten Lampe/
technical data lamp
- Leuchtmittel/illuminant : 5.0W CREE LED
 - Lebensdauer/Life-time : ca./approx. 50.000h
 - Zellenzahl/number of cells : 4x AAA Micro 1.5V Batterien/batteries (Alkaline; LR03/AM4/MN2400)
 - Schalterfunktion/switch function : Multifunktionschalter multi-function switch
 - Leuchtweite (ANSI FL1)/beam range (ANSI FL1) : 220m
 - Sichtweite/visual range : 700m
 - Leuchtdauer/operating time : 17h bei 20% Helligkeit/brightness at 20%
3h bei 100% Helligkeit/brightness at 100%
 - Helligkeit/brightness : 220 Lumen
13000 Lux
 - Schutzart/protection : IP67
 - Gehäuse/housing : Aluminiumgehäuse, schwarz eloxiert aluminiumhousing, black anodized
 - Gewicht/weight : 188g inkl. Batterien/188g incl. batteries
 - Approbationen/approvals : CE
 - Zubehör/attachments : - 8x Micro AAA 1.5V Batterien/batteries (Alkaline; LR03/AM4/MN2400)
- Tragegurt/lanyard
- Gürtelclip/belt clip

Gelber Aufkleber auf dem Lampenkopf/
yellow sticker on the head of the torch


weißer Aufkleber mit schwarzer Bedruckung/
white sticker with black printing

schwarzer Aufkleber mit weißer Bedruckung/
black sticker with white printing

Batteriehalter für 4x AAA Micro/
battery holder for 4x AAA micro

Multifunktionschalter (Schalt- und Tastfunktion)
Schaltfunktion: An/Aus
Tastfunktion: 1. 100% Helligkeit
2. 20% Helligkeit
3. Blinkfunktion mit 100% Helligkeit
4. Kurzzeitiges Anschalten
(solange getastet wird; nur im ausgeschalteten Zustand)

Multi-function switch (switch and push-button function)
Switch function: On/Off
Push-button function: 1. 100% brightness
2. 20% brightness
3. flash function with 100% brightness
4. momentary turning on
(as long as being pushed; only when turned off)

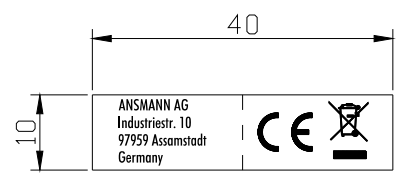

Flagge am Tragegurt
flag at the carrying belt

Verwendungsbereich/Application range für Anfrage/for inquiry AN201167A5				Zul. Abweichung/ Allowable deviation	Oberfläche/ Surface	Maßstab/Scale (DIN A3): 1:1	Gewicht/Weight
						Werkstoff/Work material, Modell-Nr.	
				2012	Datum/Date	Name	
V2	technical data updated	16.09.14	SIT	Erstellt/ Drawn by	15.06	SIT	
V2	date code changed and address added	21.01.14	CF			Zeichnungsname/Drawing name	
V1	technical data updated	28.08.13	CB			Agent FIVE – neues Design/ Agent FIVE – new Design	
V0	Clip added in drawing	19.08.13	DC			Zeichnungsnummer/Drawing number	
V0	technical data updated	28.03.13	DC			Artikelnummer/Part number	
V0	technical data updated	08.08.12	DC			1600-0036	
V0	---	25.07.12	DC			Blatt/ Sheet	
Version Änderung/Change Datum/Date Name				Ursprung/Origin Proj. 060/22/12		Ersatz für/Replaced by	
						Ersatz durch/Replacement through	

