


LO-tox™ Filled Laboratory Thermometers

LO-tox™ is an organic filling specially chosen to achieve a wide temperature span and provide the lowest practical levels of hazard. The quality and legibility make these an ideal substitute for mercury thermometers. Fitted with Brannan non roll end cap which has a ring to allow the thermometer to be suspended.

Product Specifications

Product Material:	Glass Tube: Kerosene filled (except * - special brown filling for high range) Non-roll end cap - Evoprene
Product Dimension:	6.5mm dia x length (see table below)
Product Net Weight:	155mm - 8.6g 305mm - 24.4g 405mm - 34.0g
CE:	N/A
ROHS/WEEE:	N/A
Hazard Information (SDS):	See www.brannan.co.uk for information

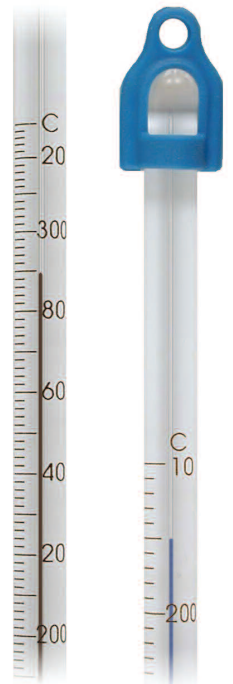

Range °C	Division	Tube Length	Filling Colour	76mm Immersion		Total Immersion	
				Product No	Accuracy	Product No	Accuracy
-10 to +50	1.0	155mm	Blue	-	-	44/850/7	+/-1.0°C @ 35°C
-10 to +110	1.0	155mm	Blue	-	-	44/830/7	+/-1.5°C @ 35°C
-35 to +50	1.0	305mm	Blue	44/801/8	+/-1.0°C @ 35°C	44/809/8	+/-1.0°C @ 35°C
-10 to +50	0.5	305mm	Blue	44/800/8	+/-0.5°C @ 35°C	44/808/8	+/-0.5°C @ 35°C
-20 to +110	1.0	305mm	Blue	44/802/8	+/-1.0°C @ 35°C	44/810/8	+/-1.0°C @ 35°C
-20 to +110	0.5	305mm	Blue	44/802/9	+/-1.0°C @ 35°C	44/810/9	+/-1.0°C @ 35°C
-20 to +150	1.0	305mm	Blue	44/803/8	+/-1.0°C @ 35°C	44/811/8	+/-1.0°C @ 35°C
-10 to +210	1.0	405mm	Blue	44/805/8	+/-2.0°C @ 90°C	44/812/8	+/-2.0°C @ 90°C
-10 to +260	1.0	405mm	Blue	44/804/8	+/-2.0°C @ 90°C	44/813/8	+/-2.0°C @ 90°C
-10 to +300	1.0	305mm	Brown	44/815/0*	+/-2.0°C @ 90°C	44/818/0	+/-2.0°C @ 90°C
-10 to +330	2.0	305mm	Brown	44/814/0*	+/-2.0°C @ 90°C	44/827/0	+/-2.0°C @ 90°C
-10 to +360	2.0	305mm	Brown	44/826/8*	+/-2.0°C @ 90°C	44/819/0*	+/-2.0°C @ 90°C
-1 to +51	0.1	405mm	Blue	44/820/0	+/-1.0°C @ 35°C	44/821/0	+/-0.5°C @ 35°C
-1 to +51	0.2	405mm	Blue	44/822/0	+/-1.0°C @ 35°C	44/823/0	+/-0.5°C @ 35°C
-1 to +101	0.2	405mm	Blue	44/824/0	+/-1.0°C @ 35°C	44/825/0	+/-0.4°C @ 35°C

The following specifications are for packed thermometers.
Each thermometer is supplied in protective PVC packing (6g PVC per thermometer)
Pack of ten thermometers supplied in cardboard box
Box Weight: 155mm Thermometer Box - 18g
305mm Thermometer Box - 45g
405mm Thermometer Box - 47g

Tube Length	Single Packed Thermometer		Pack of 5 Thermometers		Boxed Pack of 10	
	Weight	Dimensions	Weight	Dimensions	Weight	Dimensions
155mm	14.6g	190 x 23 x 14mm	73g	190 x 115 x 14mm	164g	195 x 70 x 40mm
305mm	30.4g	335 x 23 x 14mm	152g	335 x 115 x 14mm	346g	340 x 72 x 40mm
405mm	40.0g	435 x 23 x 14mm	200g	435 x 115 x 14mm	447g	440 x 72 x 40mm

PDS 2002:14:R2