

## 638866

EMEA Region

### BRIGHT

- Powerful LED provides 110 lumens in All LEDs mode
- Useable light for 24 hours in Area Low mode. Using Energizer<sup>®</sup> MAX<sup>®</sup> batteries



### CONVENIENT

- Pivots to aim light where you need it
- Adjustable elastic headband



### WEATHERPROOF

- Meets IEC 60529 IPX4 standards
- Continues to operate after exposure to splashing water from all directions



### VERSATILE

- Five lighting modes
  - All LEDs
  - Spot High
  - Spot Light
  - Area High
  - Area Low



Lightweight, versatile and comfortable, the Energizer<sup>®</sup> 5-LED Headlight is perfect for any job that requires both hands. It puts light where you are looking and has a swivel adjustment with ratchet positioning for accurate aim.

Variable light sources allow you to choose the best illumination for the job – flood or spot – without changing lights. Also, this light can be worn comfortably around the head for long periods of time.



**Before Using Your Flashlight:**  
Please read all instructions and cautionary markings on the package and light

### Product Detail:

**Designation:** Energizer 5-LED Headlight  
**SAP:** 638866  
**Colour:** Yellow  
**Power Source:** Three "AAA"  
**IEC:** LR03  
**Lamp:** 4 White Nichia LEDs, 1 White Cree LED

**Lamp Life (hr):** Lifetime


Mode:	All LEDs	Spot High	Spot Low	Area High	Area Low
<b>Lamp Output (lumens):</b>	110	160	85	60	30
<b>Run Time (h:mm)</b>	4	4:30	10	12	24
<b>Beam Distance (m):</b>	80	75	55	35	25
<b>Peak Beam Intensity (cd):</b>	1580	1440	755	330	156

**Typical Weight:** 107 grams with 3 Alkaline AAA batteries  
71.7 grams without batteries

**Dimensions (mm):** 45 x 63 x 42

### Performance:

**Run Time**  
Continuous Drain to  
End of Useable Light (21° C)

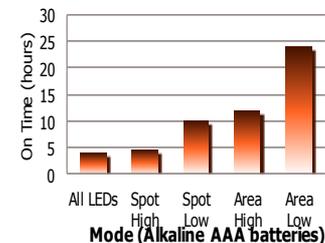

*Tested according to ANSI/NEMA FL 1 Standards.*

### Important Notice

This datasheet contains information specific to products manufactured at the time of its publication  
**Contents herein do not constitute a claim or warranty**  
 ©Energizer / All Rights Reserved