



EMEA Region

## BRIGHT



- LED provides 200 lumens of light on high, 60 on low.
- LED bulb provides bright white light for tough jobs

## ECONOMICAL



- Useable light for 17 hours with Energizer® MAX batteries.
- LED never needs replacing

## WEATHERPROOF



- Meets IEC 60529 IPX4 standards
- Continues to operate after exposure to splashing water from all directions

## DURABLE



- Survives a 7-meter drop

# 639826

EMEA Region

The Toughest Flashlight You'll Ever Need. The new Energizer® Hard Case Professional® Magnet Headlight delivers improved brightness, compact design, and hands-free design features. The headlight has a detachable light module magnet that can be used for Industrial tasks, providing alternate hands-free convenience and product versatility.



**Before Using Your Flashlight:**  
Please read all instructions and cautionary markings on the package and light

## Product Detail:

**Designation:** Energizer  
Hard Case Pro Magnet Headlight

**SAP:** 639826

**Colour:** Black, Orange and Grey

**Power Source:** Three "AAA"

**IEC:** LR03

**Lamp:** Two White LEDs

**Lamp Life (hr):** Lifetime

**Mode:**

High	Low
200	60
3:30	17
65	30
1,050	295

**Lamp Output (lumens):**

**Run Time (h:mm):**

**Beam Distance (m):**

**Peak Beam Intensity (cd):**


**Typical Weight:** 135 grams with batteries

**Dimensions (mm):** 63.5 x 44.45 x 44.45

## Performance:

### Run Time

Continuous Drain to  
End of Useable Light (21° C)

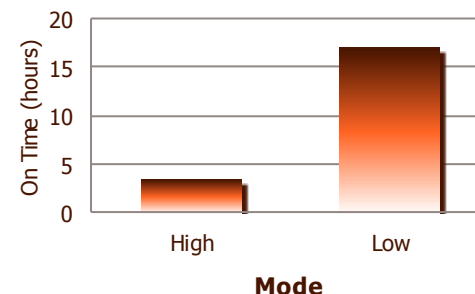

*Tested according to ANSI/NEMA FL 1 Standards.*

### Important Notice

This datasheet contains information specific to products manufactured at the time of its publication  
**Contents herein do not constitute a claim or warranty**  
©Energizer / All Rights Reserved