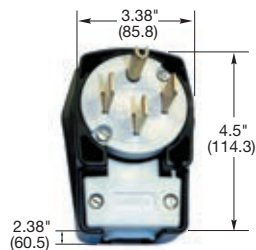
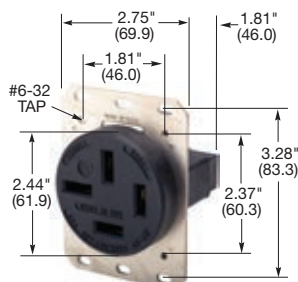
**HBL9450A****HBL9451C****HBL9452C****HBL8350A**
**50A, 125/250V,
3 Pole, 4 Wire Grounding,
Receptacles and Plugs**
IP20
SUITABILITY

**50A 125/250V
NEMA 14-50R**
UL CSA
3(2) HP

**50A 125/250V
NEMA 14-50P**
UL CSA
3(2) HP

Description	Cord Diameter	Catalog Number
Receptacle, black RTP.	—	HBL9450A
Plug, nylon.	.625"-1.310" (15.9-33.3)	HBL9451C
Plug, nylon, angle, 4-position.	.625"-1.310" (15.9-33.3)	HBL9452C

**50A, 3Ø 250V AC,
3 Pole, 4 Wire Grounding,
Receptacles and Plugs**
IP20
SUITABILITY

**50A 3Ø 250V AC
NEMA 15-50R**
UL CSA
7.5 HP

**50A 3Ø 250V AC
NEMA 15-50P**
UL CSA
7.5 HP

Description	Cord Diameter	Catalog Number
Receptacle, black RTP.	—	HBL8450A
Plug, nylon.	.625"-1.310" (15.9-33.3)	HBL8451C
Plug, nylon, angle, 4-position.	.625"-1.310" (15.9-33.3)	HBL8452C


**50A, 3ØY 120/208V AC,
4 Pole, 4 Wire Non-Grounding,
Receptacles and Plugs**
IP20
SUITABILITY

**50A 3ØY
120/208V AC
NEMA 18-50R**
UL Listed
7.5 HP

**50A 3ØY
120/208V AC
NEMA 18-50P**
UL Listed
7.5 HP

Description	Cord Diameter	Catalog Number
Receptacle, black RTP.	—	HBL8350A
Plug, nylon, angle, 4-position.	.625"-1.310" (15.9-33.3)	HBL8352C

Note: RTP is an abbreviation for reinforced thermoplastic polyester.
See page A-49 for accessories.