


**KEMET Part Number: PME271E522MR30**  
(P277QN223M300A)



Capacitor, film, 0.022 uF, +/-20% Tol, -40/+110C, Safety: X1, 300 VAC, Lead Spacing=15.2 mm

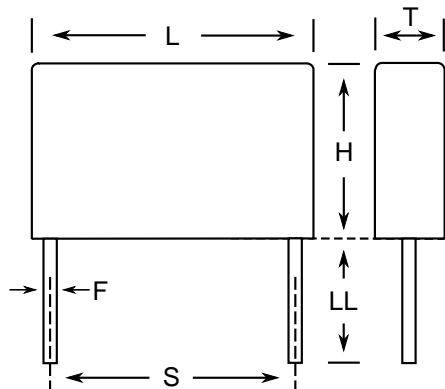

Dimensions (mm)		
Symbol	Dimension	Tolerance
L	19	MAX
H	13	MAX
T	7.3	MAX
S	15.2	+/-0.4
LL	30	+5
F	0.8	+/-0.05

Packaging Specifications	
Package Kind:	Bulk
Package Quantity:	400

General Information	
Supplier:	KEMET
Dielectric:	Metallized Paper
Application:	Safety: X1
Style:	Radial Molded
Lead Form:	Wire Leads
Approvals:	ENEC,UL
RoHS:	Yes

Specifications	
Capacitance:	0.022 uF
Voltage:	630 VDC
Tolerance:	+/-20%
Voltage AC:	300 VAC
Rated Temperature:	110C
Temperature Range:	-40/+110C
Dissipation Factor @ 1 kHz:	1.3%
Insulation Resistance:	12 GOhm
Maximum dVdT:	1200 v/us
Miscellaneous:	SRF= 9.8 MHz