

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1510492200

Status:


Active

Overview:

CP-6.5 Wire-to-Board Connector System

Description:

CP-6.5 Receptacle Housing, 6.50mm Pitch, Dual Row, Polarized, Positive Lock, 2 Circuits, Orange

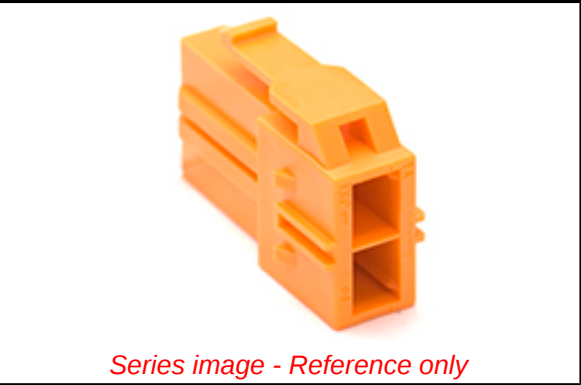

Documents:	
3D Model	Product Specification PS-151048-0001 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Housings
Series	151049
Application	Wire-to-Board
Comments	See Product Specification for maximum current rating by circuit size and wire AWG
Overview	CP-6.5 Wire-to-Board Connector System
Product Name	CP-6.5
UPC	889056065658
Physical	
Circuits (maximum)	2
Color - Resin	Orange
Gender	Female
Glow-Wire Compliant	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	PBTP
Net Weight	1.007/g
Number of Rows	2
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	6.50mm
Pitch - Termination Interface	6.50mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40°C to +105°C
Electrical	
Current - Maximum per Contact	10.0A
Solder Process Data	
Lead-freeProcess Capability	N/A
Material Info	
Reference - Drawing Numbers	
Product Specification	PS-151048-0001
Sales Drawing	SD-151049-0001

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant

REACH SVHC

Contains SVHC(2015 June 15): No

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com

Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Green Image

ELV

Not Relevant

Search Parts in this Series

151049 Series

Mates With

CP-6.5 Headers 151048-1200 , 151048-2200

Use With

Female Crimp Terminal 16-22 AWG Wire 50597-8000 , Female Crimp Terminal 20-26 AWG Wire 50598-8000 , Crimp Terminal Retainer 51143-0105

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION