


VGA over Cat5/Cat6 Extender Kit, Transmitter & Receiver with EDID, 2 Local/2 Remote Displays, 1440x900, Up to 500-ft.

MODEL NUMBER: **B130-202**

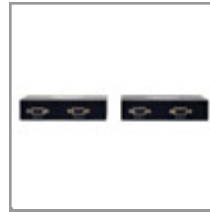

Description

Tripp Lite B130-202 allows you to extend two 1024x768 VGA video signals up to 500 ft., over ordinary Cat5e cable, from a single VGA source. The Transmitter / Receiver kit also features two local VGA HD15 ports, supporting a total of four VGA monitors (2 Local and 2 Remote). Compatibility issues can occur when EDID information is not properly communicated between the source and the display. The B130-202 includes an EDID copy feature which stores a monitor's EDID information in the transmitter and sends it to the source, ensuring optimal compatibility. Supports all operating systems, and is plug-and-play...no software or drivers required.

Features

- Connect up to four monitors; 2 local and 2 remote
- Extends a 1440 x 900 @ 60Hz signal up to 165 ft. (50 m) from the source
- Extends a 1024 x 768 @ 60Hz signal up to 500 ft. (150 m) from the source
- EDID copy feature ensures optimal display compatibility
- Built-in equalization control allows for adjustment of the video image
- All operating systems supported
- Plug-and-play; no software or drivers are required
- HDCP compliant

Specifications

OVERVIEW	
Display Style	Extender
Cable Type	UTP (Cat5, Cat5e, Cat6, Cat6a); VGA

Highlights

- Extends a VGA signal up to 500 ft.
- Connect up to four VGA monitors: 2 Local and 2 Remote
- EDID copy feature ensures optimal display compatibility

System Requirements

- PC with VGA video output
- Monitors with VGA input

Package Includes

- B130-202 Transmitter Unit
- B130-202 Receiver Unit
- (x2) external power supplies (Input: 100-240V, 50/60Hz, 0.5A Output: 5V, 2A)
- Screwdriver for equalization adjustment
- Owner's manual



Tripp Lite
1111 W. 35th Street
Chicago, IL 60609 USA
Telephone: 773.869.1234
www.tripplite.com

PHYSICAL	
Shipping Weight (lbs.)	1.80
Shipping Weight (kg)	0.82
Unit Dimensions (hwd / in.)	Transmitter: 1.06 x 4.50 x 2.44 Receiver: 1.06 x 4.50 x 2.44
Unit Dimensions (hwd / cm)	Transmitter: 2.69 x 11.43 x 6.2 Receiver: 2.69 x 11.43 x 6.2
ENVIRONMENTAL	
Operating Temperature Range	32 to 122 F (0 to 50 C)
Storage Temperature Range	-4 to 158 (-20 to 70 C)
CONNECTIONS	
Connector A	HARDWIRE
Connector B	HARDWIRE
Ports	2
Local Console Ports	1 x RJ45, 3 x HD15F
Remote Console Port	1 x RJ45, 2 x HD15F
SPECIAL FEATURES	
Chromebook Compatible	No
WARRANTY	
Product Warranty Period (Worldwide)	1-year limited warranty

© 2015 Tripp Lite. All rights reserved. All product and company names are trademarks or registered trademarks of their respective holders. Use of them does not imply any affiliation with or endorsement by them. Tripp Lite has a policy of continuous improvement. Specifications are subject to change without notice. Tripp Lite uses primary and third-party agencies to test its products for compliance with standards. See a list of Tripp Lite's testing agencies:
<http://www.tripplite.com/products/product-certification-agencies>