

7025B-MTG

TO-220, TO-220-single gauge (0.020")




Channel style heat sink with folded back fins and solderable mounting tabs



This non-electronic component is functionally unaffected by the normal soldering or reflow processes used for semiconductor circuits. The heat resistance time or heat resistance temperature is not applicable for the component.

Height: 28.70
Mount Orientation: Vertical
Finish: Black Anodize
RoHS: compliant

Thermal Resistance: 6.80

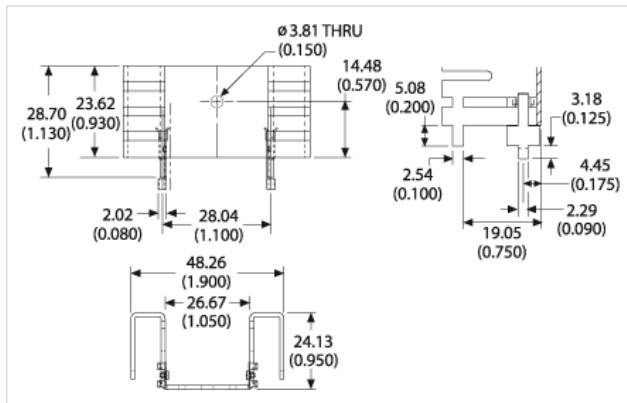

X Dim: 13.97 (0.550) | Y Dim: 3.18 (0.125) | Z Dim: 3.10 (0.122)

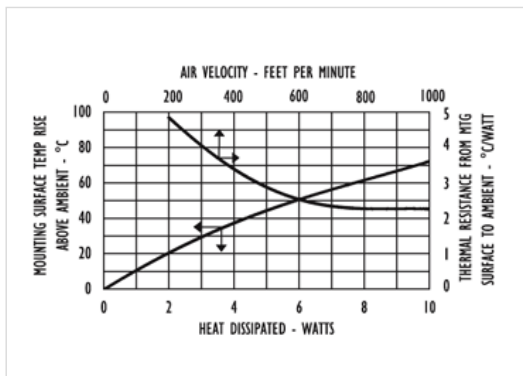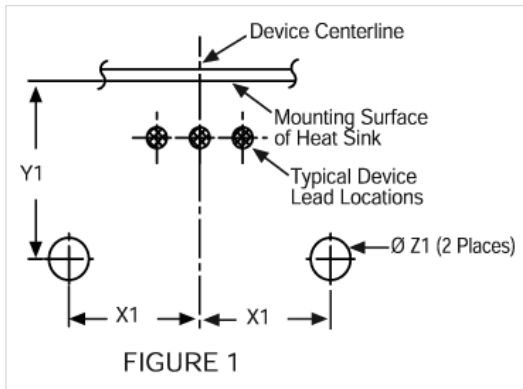

Solderable Mounting Tabs