




Splice Closures & Sheath Repair

Buried Closures

KLIK-IT® Buried Service Wire Closures

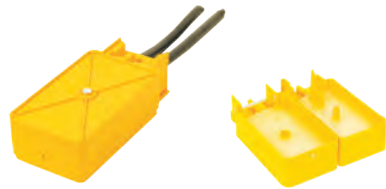

25 Pair KLIK-IT



Butt Splice




In-Line Splice

A range of filled, two-piece closures designed permanent splice encapsulation of 2 to 25 pair buried service drops. Economical and easy-to-install, these closures go together quickly and are ready for burial as soon as the splice is completed.

Design Features:

- Tough durable two-piece plastic housing- “clicks” tightly closed
- Pre-packed with grease type re-enterable encapsulant
- Water resistant
- Grease surrounds the splice connectors preventing corrosion and electrical shorting
- Re-enterable
- Optional strain relief and bonding hardware on some models
- Packaged in shrink-wrap for longer shelf-life and ease of transportation
- Straight and butt splice versions available
- Models C8825 and C88320 conform to Bellcore TR-NWT-000251

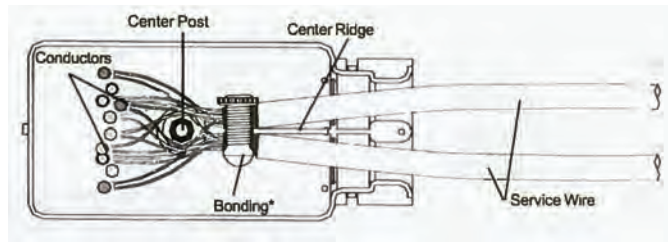

Part Number	Description	Max Pair	Splice Style	Strain Relief	Bonding	Outer Pack	Inner Pack	Min Order QTY
BUTT SPLICE KLIK-IT								
C8811	Standard KLIK-IT II	5	Butt	No	Barrel	72	-	72
C8811BCT	Wide Neck KLIK-IT II	5	Butt	Yes	None	72	-	72
C8811G	Standard KLIK-IT II with Bond Stud Coin	5	Butt	No	Bond Coin	72	-	72
C8816	Standard KLIK-IT II w/out grounding	5	Butt	No	None	72	-	72
C8816KB	Standard KLIK-IT II with Strain Relief	5	Butt	Yes	None	72	-	72
C8820	Standard KLIK-IT III	5	Butt	Yes	Integral	72	-	72
C885611X	KLK-IT II 6 pair	6	Butt	No	Split Bolt	72	-	72
C8812	Large Capacity KLIK-IT	25	Butt	No	None	15	-	15
STRAIGHT SPLICE KLIK-IT								
C8813	Standard KLIK-IT SS	5	Straight	No	Barrel	1152	48	48
C8815	Standard KLIK-IT SS w/out Grounding	5	Straight	No	None	1152	48	48
C8825	Standard KLIK-IT SSIII	5	Straight	Yes	Integral	1152	48	48
STRAIGHT SPLICE KLIK-IT FOR COPPER AND COAX CABLE								
C8826U	KLIT-IT SSC with with Coax Connector	5	Straight	No	None	1152	48	48