

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0050375023
Status: Active
Overview: SPOX™ Wire-to-Board Connectors
Description: 2.50mm Pitch SPOX™ Wire-to-Board Crimp Housing, Friction Lock, 2 Circuits

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-5264-001 \(PDF\)](#)
[Packaging Specification SPK-5264-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)


Agency Certification
UL E29179

General
Product Family Crimp Housings
Series 5264
Application Signal, Wire-to-Board
MolexKits Yes
Overview SPOX™ Wire-to-Board Connectors
Product Name SPOX™
UPC 800753578340

Physical
Circuits (maximum) 2
Flammability 94V-0
Gender Female
Glow-Wire Compliant No
Net Weight 119.300/mg
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 2.50mm
Polarized to Mating Part Yes
Stackable No
Temperature Range - Operating -40°C to +105°C

Material Info
Old Part Number 5264-02

Reference - Drawing Numbers
Packaging Specification SPK-5264-001
Product Specification PS-5264-001, RPS-5264-001, RPS-5264-002, RPS-5264-003, RPS-5264-004, RPS-5264-005, RPS-5264-006
Sales Drawing SD-5264-N

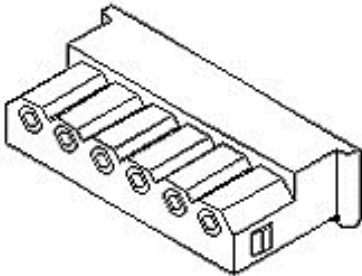

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Contains SVHC(2015 June 15): No
Halogen-Free
Status
Low-Halogen
Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS Green Image
ELV Not Relevant

Search Parts in this Series
5264 Series

Mates With
5267 vertical shrouded PCB header, 5268 right angle shrouded PCB header

Use With
5263

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION