

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0050579006

Status:

Active

Overview:

SL™ Modular Connectors

Description:

SL™ Crimp Housing, Single Row, Version A, Non-polarized, 6 Circuits

Documents:

- 3D Model

Product Specification PS-71851 (PDF)
- Drawing (PDF)

Test Summary TS-70058-001 (PDF)
- Product Specification PS-70058 (PDF)

RoHS Certificate of Compliance (PDF)
- Product Specification PS-70400 (PDF)

Agency Certification

CSA

LR19980

UL

E29179

General

Product Family

Crimp Housings

Series

70066

Application

Signal, Wire-to-Board

Comments

Version A

Overview

SL™ Modular Connectors

Product Name

SL™

UPC

800753578197

Physical

Circuits (maximum)

6

Color - Resin

Black

Flammability

94V-0

Gender

Female

Glow-Wire Compliant

No

Keying to Mating Part

None

Lock to Mating Part

No

Material - Resin

Polyester Alloy

Net Weight

0.280/g

Number of Rows

1

Packaging Type

Bag

Panel Mount

No

Pitch - Mating Interface

2.54mm

Stackable

Yes

Temperature Range - Operating

-40°C to +105°C

Electrical

Current - Maximum per Contact

3.0A

Solder Process Data

Lead-freeProcess Capability

N/A

Material Info

Old Part Number

70066-0005

Reference - Drawing Numbers

Product Specification


PS-70058, PS-70400, PS-71851

Sales Drawing

SD-70066-0001-0024

Test Summary

TS-70058-001

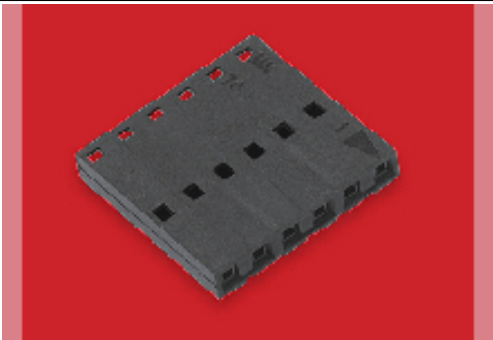

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Contains SVHC(2014 December 17): No

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

Green Image

Not Relevant

Search Parts in this Series

70066 Series

Mates With

42375 , 42377 , 70280 , 70287 , 71308 , 70543 , 7 0553

Use With

SL™ Crimp Terminal 70058 , 71851

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION