

340-9089 (888-6717)


# BRADY'S PORTABLE PRINTING SOLUTIONS

*Are you spending a lot of time and money identifying your products? Have you had enough of trimming your labels to fit your precise application? BRADY provides effective and economical portable printing solutions for all of your identification needs, from marking cables and wires to outlets, patch panels and rating plates.*

*Both of BRADY's portable printers allow you to create labels on site in no time, eliminate label waste and prevent unreadable markings.*

## I.D. PRO™ Plus Portable Printer

**The smallest, most economical label printer.**

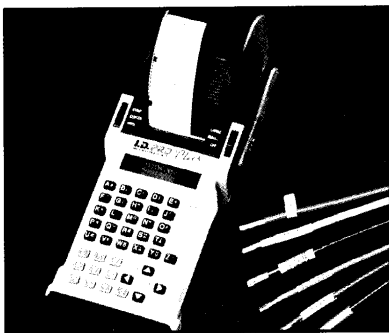

**Clever:** The I.D. PRO™ Plus Portable Printer is a lightweight, palm-sized unit with a rechargeable battery which can be plugged into your car's cigarette lighter.

**Easy to use:** The I.D. PRO™ Plus Portable Printer simplifies your work. Its LCD display provides simple, easy-to-read instructions and previews the information to be printed, eliminating the need to systematically consult a manual.

**Robust:** Its rugged ergonomic design includes shock-absorbent bumpers which protect it from damage in the field.

**Great value:** The I.D. PRO™ Plus Portable Printer offers you great results at an affordable price.

## TLS2200™ Portable Thermal Transfer Printer



**The ultimate answer to your toughest labelling challenges.**

**Easy to use:** Simply select the type of labels you need and load them into the TLS2200™ Portable Thermal Transfer Printer. It takes care of the rest, saving you a significant amount of set-up time.

**High print quality:** The TLS2200™ Portable Thermal Transfer Printer is a complete thermal transfer (THT) system. THT printing technology ensures that your labels will be smearproof and highly readable, time after time.

**Autotext sizing:** The printer reads your label style, selects a suitable type size and registers it for instant printing.

**Serial port:** A computer interface for future upgrades means that as the capabilities of the TLS2200™ Portable Thermal Transfer Printer evolve, your printers can grow as well. A quick upload will upgrade your printer to its maximum capabilities.

**Smart-cell label identification:** BRADY's smart cell tells the printer everything it needs to know about your label. The printer will recognise the label size then automatically choose the best printing parameters including text size.

**With over 200 label types and sizes from which to select, "one size does not fit all." BRADY offers you the precise label for your application.**


**TLS2200™ Portable  
Thermal Transfer Printer**

*New features  
(available mid-November '99):*

- Banner (horizontal and vertical) printing on 12,7 mm, 25,4 mm and 48,3 mm continuous tapes
- PC-compatibility with direct printing from LABELMARK/WIN™ Labelling Software


**Specifications:**

- Weight: 1,25kg
- Thermal transfer print mechanism: 203dpi
- Print speed: 25,4 mm/sec
- Custom True Type font
- Labels up to 50,8 mm
- Print width : 46 mm
- Two line LCD, 16 characters wide
- Operating temperature range: 4°C-49°C
- UL and CUL listed battery charger - 220V/50hz input 9VDC 183mA output
- FCC Class A approved
- CE approved
- Prints over 500 labels between battery charges
- 6 month warranty
- Adjustable material guide for 6 different widths of labels
- Built-in cutter
- Rechargeable NiCad battery
- Rugged ABS/Polycarbonate housing

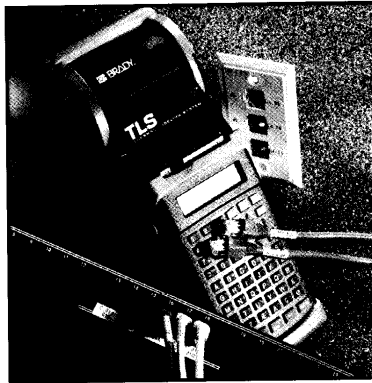

**Accessories:**

- AC adapter
- Battery pack
- Battery charger
- Hard-side carrying case
- Soft-side user's case
- Cleaning kit PCK-5 (includes 5 cleaning cards)
- Available Ribbons: R-4310, R-6010, R-6210

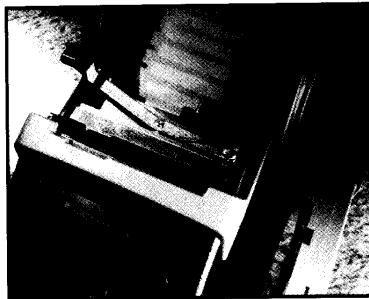

*For more detailed information on the TLS2200™ Portable Thermal Transfer Printer, please ask for your TLS2200™ Material Advantage Guide or check out our website at [www.tls2200.com](http://www.tls2200.com)*

**I.D. PRO™ Plus  
Portable Printer**

**Specifications:**


- Weight: 730g
- Print technology: Dot matrix
- Two-line LCD, max. 16 characters wide
- Prints up to 8 variable lines of text
- Two type sizes with bold and normal available
- Prints up to 250 labels between battery charges
- Operating temperature range: 4°C-49°C
- UL listed battery charger, 120 VAC, 60hz input/ 9V DC 75 mA output
- FCC Class A approved
- CE approved
- 6 month warranty
- Shock-absorbent bumpers for increased durability
- 3 different label widths (15 mm, 25,4 mm and 38 mm)

**Accessories:**

- Hard storage case
- 12-volt cigarette lighter charger
- Battery charger
- Printer cleaning kit (PCK-4)
- Battery pack

**Ribbons:**

- R-5300: black high-performance ribbon for PERMASLEEVE™ markers
- R-7300: black high-performance ribbon for all labels, BRADYSLEEVE™ and DURASLEEVE™ markers

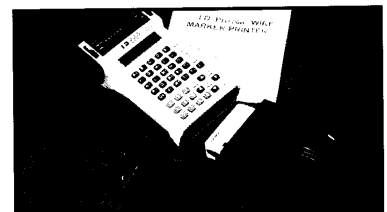

**In contact with BRADY Europe**

**261 E**

BRADY  
BELGIUM  
Lindestraat, 20  
9240 Zele  
Phone : 32 (0) 52 457 811  
Fax : 32 (0) 52 457 812  
[www.brady.be](http://www.brady.be)

BRADY  
UNITED KINGDOM  
Wildmere Industrial Estate  
Banbury, Oxon - OX16 7JU  
Phone : 44 (0) 1295 228 200  
Fax : 44 (0) 1295 228 100  
[www.brady.co.uk](http://www.brady.co.uk)

BRADY  
FRANCE  
2, Place Marcel Rebuffat  
BP-362  
91959 Les Ulis Cedex  
Phone : 33 (0)1 69 31 91 00  
Fax : 33 (0)1 69 31 10 68

BRADY  
GERMANY  
Lagerstraße, 13  
64807 Dieburg  
Phone : 49 (0) 6071 960 3  
Fax : 49 (0) 6071 960 400

BRADY  
ITALY  
Via Lazzaroni, 7  
21047 Saronno (VA)  
Phone : 39 02 9670 0507  
Fax : 39 02 9670 3644

BRADY  
SWEDEN  
Karins väg, 5  
194 54 Upplands Väsby  
Phone : 46 (0) 8 590 057 30  
Fax : 46 (0) 8 590 818 68  
[www.brady.se](http://www.brady.se)

Visit our Website: [www.bradycorp.com](http://www.bradycorp.com)

