


Lamp Specification

Wamco Part No.	Envelope Size	Base Type	Rating	Filament Shape
WL-1317	B-6	BA15s	6V 0.510A	C-6

Test Volts	Current (A)			Light Output (MSCP)			Life Hours
	Min.	Nom.	Max.	Min.	Nom.	Max.	
6.0	.459	.510	.561	2.72	3.40	4.08	100 Hrs

Dimensional Characteristics:

1. L.C.L. = 1.13" (28.7mm)
2. Base = Nickel-plated Brass Construction.

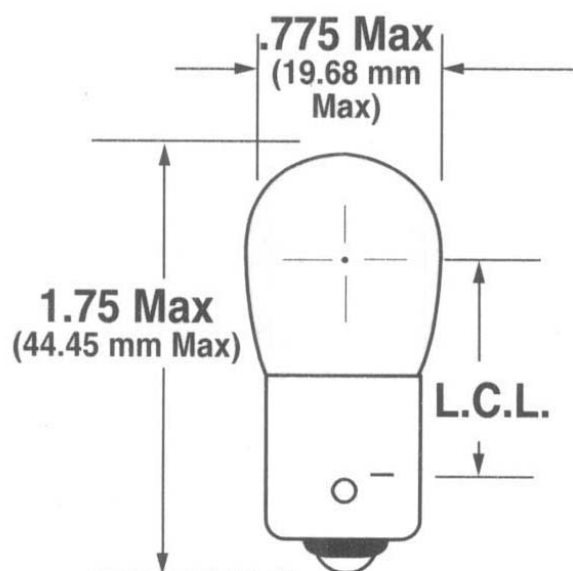

Title:

**B-6 Single Contact Bayonet Base Lamp
6V .510A Gas-Filled**

Drawn	7/19/00	CI	Notes: Unless otherwise specified, all dimensions are in inches.
Checked	7/19/00	EB	
Approved	7/19/00	EB	