


Lamp Specification

Wamco Part No.	Envelope Size	Base Type	Rating	Filament Shape
WL-1385	R-12	BA15s	28V 20W	CC-8

Test Volts	Current (A)			Light Output (MSCP)			Life Hours
	Min.	Nom.	Max.	Min.	Nom.	Max.	
28	.648	.720	.792	—	—	—	300 Hrs

Dimensional Characteristics:

1. Base = Nickel-plated Brass Construction.
2. Bottom Reflectorized Inside Frosted.

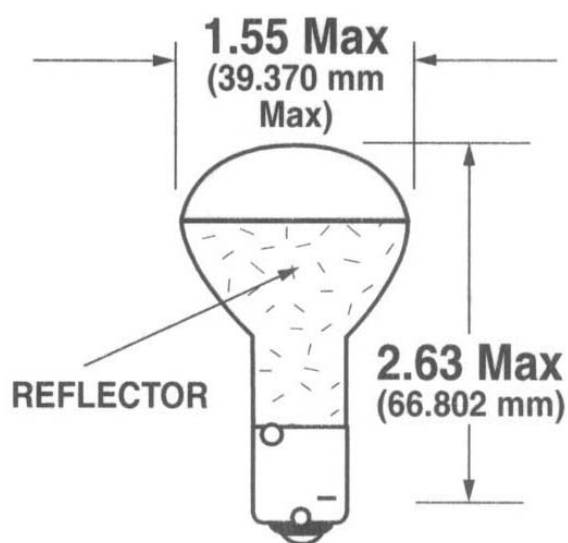

Title:

**R-12 Single Contact Bayonet Base Lamp
28V 20W Gas-Filled**

Drawn	7/31/00	CI	Notes: Unless otherwise specified, all dimensions are in inches.
Checked	7/31/00	EB	
Approved	7/31/00	EB	