

T-4½ MINIATURE BAYONET BASE

MINIATURE LAMP

28V .3A

WAMCO PART NO.

WL-1495

ENVELOPE SIZE

T-4½

BASE TYPE

BA9s

RATING

28V .3A

FILAMENT SHAPE

C-2F

TEST VOLTS

28V

MIN

.270

CURRENT (A)

NOM

.300

MAX

.330

LIGHT OUTPUT (MSCP)

MIN

4.5

NOM

6.0


MAX

7.5

LIFE HRS

500

DIMENSIONAL CHARACTERISTICS

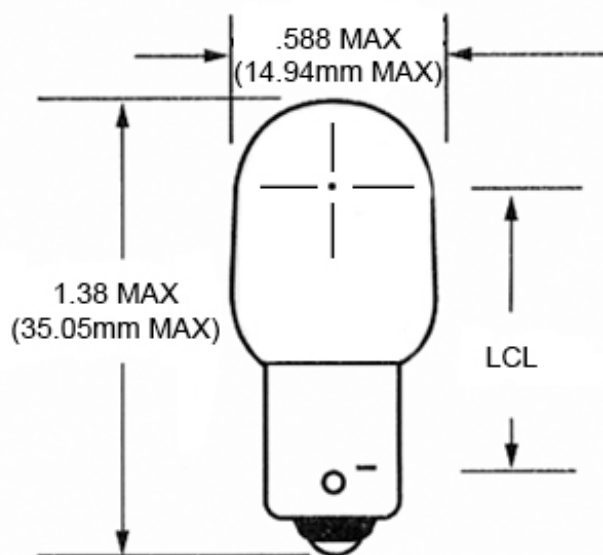

unless otherwise specified, all dimensions are inches

NOTES

1. LCL = .63" (16mm)
2. Nickel-plated brass construction base
3. Part mark WL-1495
4. RoHS compliant
5. ANSI trade number 1495
6. Military standard MS25069-1495

