


T-4½ MINIATURE BAYONET BASE

MINIATURE LAMP

28V .30A

WAMCO PART NO.		ENVELOPE SIZE	BASE TYPE	RATING	FILAMENT SHAPE		
WL-1495X		T-4½	BA9s	28V .30A	C-2F		
TEST VOLTS	CURRENT (A)		MAX	LIGHT OUTPUT (MSCP)			LIFE HRS
	MIN	NOM		MIN	NOM	MAX	
28V	.270	.300	.330	4.5	6.0	7.5	500

DIMENSIONAL CHARACTERISTICS

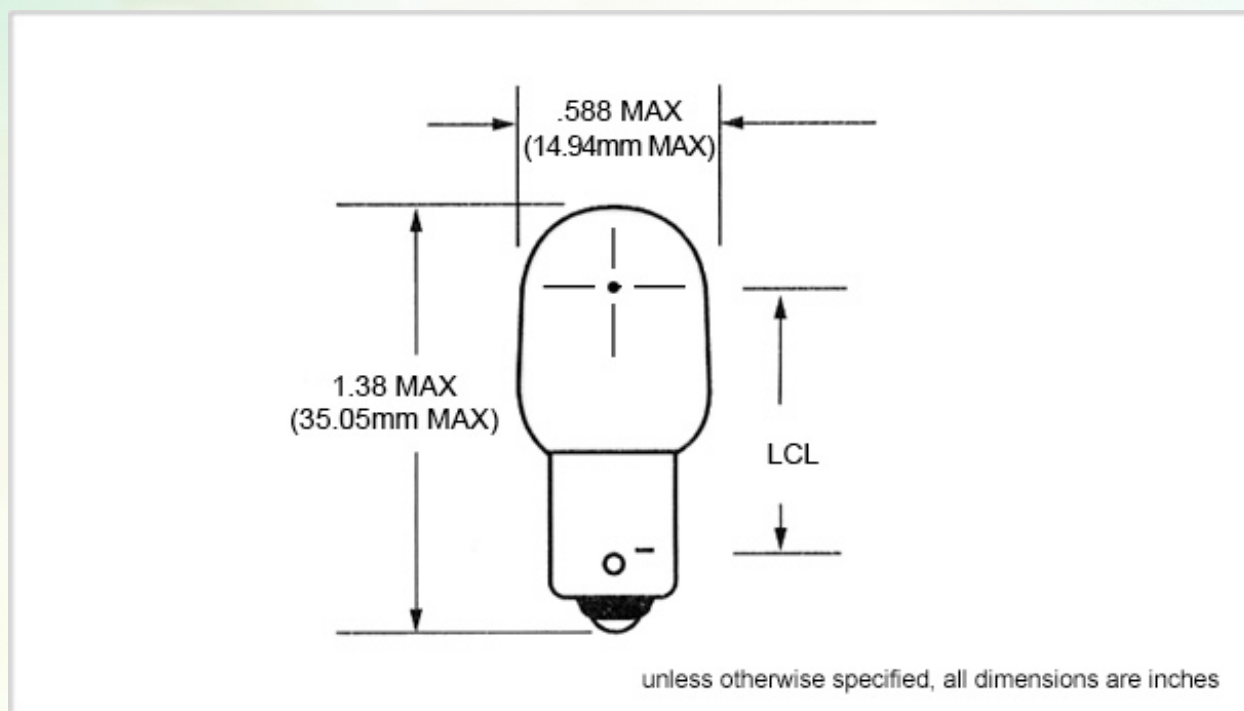

NOTES

1. L.C.L. = .63" (16mm)
2. Nickel-plated brass construction base
3. Part mark WL-1495X
4. RoHS compliant
5. ANSI trade number 1495 X

