


S-8 Single Contact Bayonet

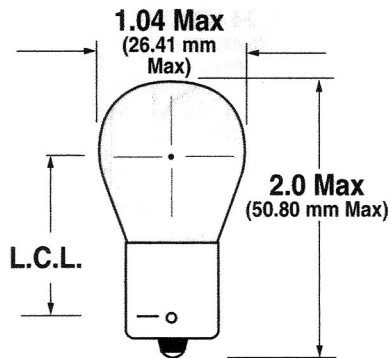

Line #	Part #	Volts	Amps	MSCP	Life	Filament	LCL
1	PL1459	4.00	.800	2.500	300	C2R	1.13
2	PL1651	5.00	.600	3.000	20	C2R	1.13
3	PL1613 #	6.00	1.500	13.000	50	C6	1.25
4	PL1680	6.00	4.100	32.000	300	C6	1.25
5	PL1129	6.40	2.630	21.000	200	C6	1.25
6	PL1605	6.40	2.690	21.000	200	C2V	1.25
7	PL1619 #	6.70	1.900	15.000	500	C6	1.13
8	PL87	6.80	1.910	15.000	300	C2R	1.13
9	PL1295	12.50	3.000	50.000	200	C2R	1.25
10	PL93	12.80	1.040	15.000	700	C6	1.13
11	PL1161	12.80	1.350	22.000	500	CC-6	1.25
12	PL1141	12.80	1.440	21.000	500	C6	1.25
13	PL1777	12.80	1.520	26.000	400	C2R	1.13
14	PL1073	12.80	1.800	32.000	200	C6	1.25
15	PL1156	12.80	2.100	32.000	1,200	C6	1.25
16	PL199	12.80	2.250	32.000	1,200	C6	1.25
17	PL1095	14.00	.510	4.000	5,000	C6	1.25
18	PL305	28.00	.510	15.000	300	C2V	1.13
19	PL1591	28.00	.610	15.000	1,000	C2V	1.13
20	PL1691	28.00	.610	15.000	1,000	2C2R	1.13
21	PL2232	28.00	.640	18.000	2,000	CC8I	1.19
22	PL307	28.00	.670	21.000	300	C2V	1.13
23	PL1203	28.00	.710	21.000	400	C2V	1.25
24	PL1563	28.00	.760	21.000	1,000	CC6	1.13
25	PL2233	28.00	.770	21.000	2,000	CC8I	1.19
26	PL1665	28.00	.800	21.000	1,000	C2V	1.13
27	PL315	28.00	.900	32.000	300	C2V	1.13
28	PL1683	28.00	1.020	32.000	500	2C6	1.25
29	PL109	44.00	.170	6.000	200	C7A	1.13

Bulb selected for minimum imperfections