


GG-12A AIRCRAFT WARNING LAMP

SINGLE CONTACT INDEX BAYONET BASE

6.2V 40W

WAMCO PART NO.		ENVELOPE SIZE	BASE TYPE	RATING	FILAMENT SHAPE
WL-16870		GG-12A	BAY15s	6.2V 40W	C-6
TEST VOLTS	CURRENT (A)			LIGHT DISTRIBUTION	LIFE HRS
	MIN	NOM	MAX		
6.2V	6.00	6.45	6.90	4800 CANDLE POWER MINIMUM ON REFLECTOR AXIS HORIZONTAL AND VERTICAL BEAM SPREAD TO 480 CANDLE POWER, 20° MINIMUM	150

DIMENSIONAL CHARACTERISTICS

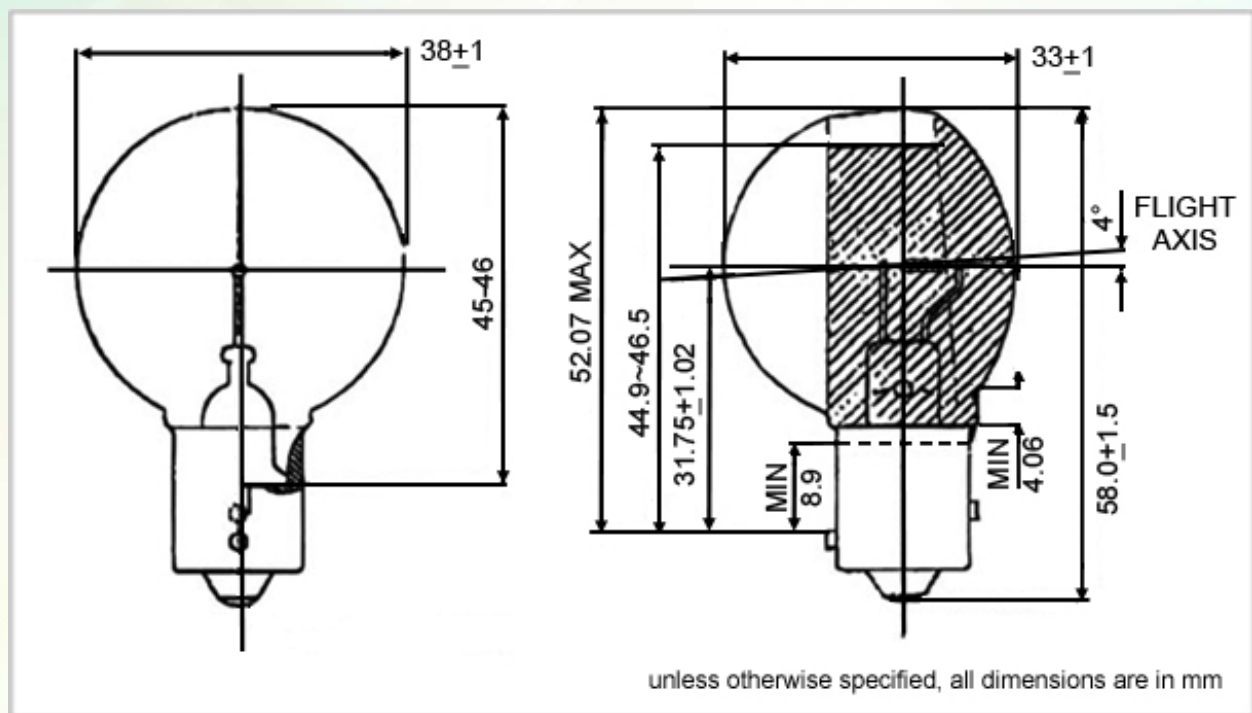

NOTES

1. Finish clear, except where reflective surface is required
2. Reflective coating must conform to the coating adhesion requirements of MIL-L-6363F, paragraph 4.6.6
3. Part mark WL-16870, 6.2V, 40W and M6363/1-3
4. RoHS compliant
5. ANSI trade number 1687
6. Military Standards M6363/1-3, MS25338-1687
7. QPL certified

