


Lamp Specification

Wamco Part No.	Envelope Size	Base Type	Rating	Filament Shape
WL-1691	S-8	BA15s	28V 0.61A	2C-6

Test Volts	Current (A)			Light Output (MSCP)			Life Hours
	Min.	Nom.	Max.	Min.	Nom.	Max.	
28.0	.549	.610	.671	12.0	15.0	18.0	1,000 Hrs

Dimensional Characteristics:

1. L.C.L. = 1.13" (28.7mm)
2. Base = Nickel-plated Brass Construction.

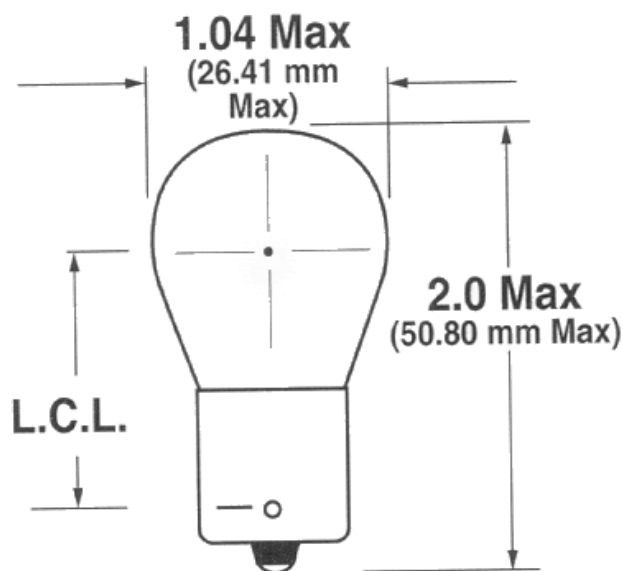

Title:

**S-8 Single Contact Bayonet Base Lamp
28V .61A Gas-Filled**

Drawn	4/24/00	CI	Notes: Unless otherwise specified, all dimensions are in inches.
Checked	4/24/00	EB	
Approved	4/24/00	EB	