


T-1^{3/4} Midget Screw

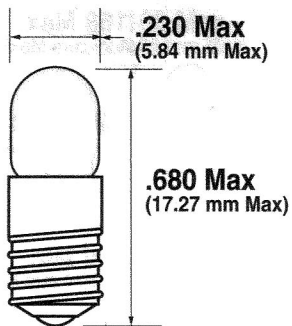

Line #	Part #	Volts	Amps	MSCP	Life	Filament
1	PL8669	1.35	.060	.010	500	C2R
2	PL1767	2.50	.200	.200	500	C2R
3	PL1769	2.50	.200	.220	500	C2R
4	PL7312	2.50	.350	.210	10,000	C2R
5	PL8671	2.50	.400	.550	30	C2R
6	PL8693	2.70	.060	.040	6,000	C2R
7	PL7313	3.00	.015	.003	10,000	C6
8	PL7314	3.00	.030	.020	1,800	C6
9	PL7315	4.50	.120	.050	25,000	C2R
10	PL2950	5.00	.017	.018	8,000	C2R
11	PL7316	5.00	.060	.030	60,000	C2R
12	PL7318	5.00	.060	.050	25,000	C2R
13	PL3153	5.00	.060	.150	5,000	C2R
14	PL7319	5.00	.115	.150	40,000	C2R
15	PL7317	5.00	.190	.450	1,000	C2R
16	PL342	6.00	.040	.030	10,000	C2V
17	PL7323	6.00	.200	.100	50,000	C2F
18	PL1768	6.00	.200	.600	1,000	C2R
19	PL7320	6.30	.040	.020	20,000	C2V
20	PL1775	6.30	.075	.230	1,000	C2R
21	PL7321	6.30	.150	.450	3,000	C2R
22	PL378	6.30	.200	.400	20,000	C2F
23	PL8687	6.30	.200	.550	5,000	C2R
24	PL8691	10.00	.014	.002	50,000	C2F
25	PL389	10.00	.040	.080	5,000	C2F
26	PL7325	11.00	.022	.030	10,000	C2F
27	PL7326	12.00	.040	.120	10,000	C2F
28	PL8362	14.00	.080	.300	15,000	C2F
29	PL373	14.00	.080	.500	1,500	C2F
30	PL8162	14.00	.100	.500	10,000	C2F
31	PL8536	18.00	.040	.150	10,000	C2F
32	PL8437	22.00	.040	.300	2,000	C2F
33	PL8178	24.00	.050	.500	1,000	C2F
34	PL8384	28.00	.040	.150	10,000	C2F
35	PL399	28.00	.040	.300	7,000	C2F
36	PL335	28.00	.040	.340	4,000	C2F
37	PL369	28.00	.040	.340	4,000	C2F
38	PL335LSV	28.00	.060	.340	25,000	C2F
39	PL8369	28.00	.065	.650	5,000	C2F