


T-3¼ MINIATURE BAYONET BASE

MINIATURE LAMP

14.4V .100A

WAMCO PART NO.		ENVELOPE SIZE	BASE TYPE	RATING	FILAMENT SHAPE		
WL-1813		T-3¼	BA9s	14.4V .100A	C-2V		
TEST VOLTS	CURRENT (A)			LIGHT OUTPUT (MSCP)			LIFE HRS
	MIN	NOM	MAX	MIN	NOM	MAX	
14.4V	.090	.100	.110	.645	.860	1.075	1,000

DIMENSIONAL CHARACTERISTICS

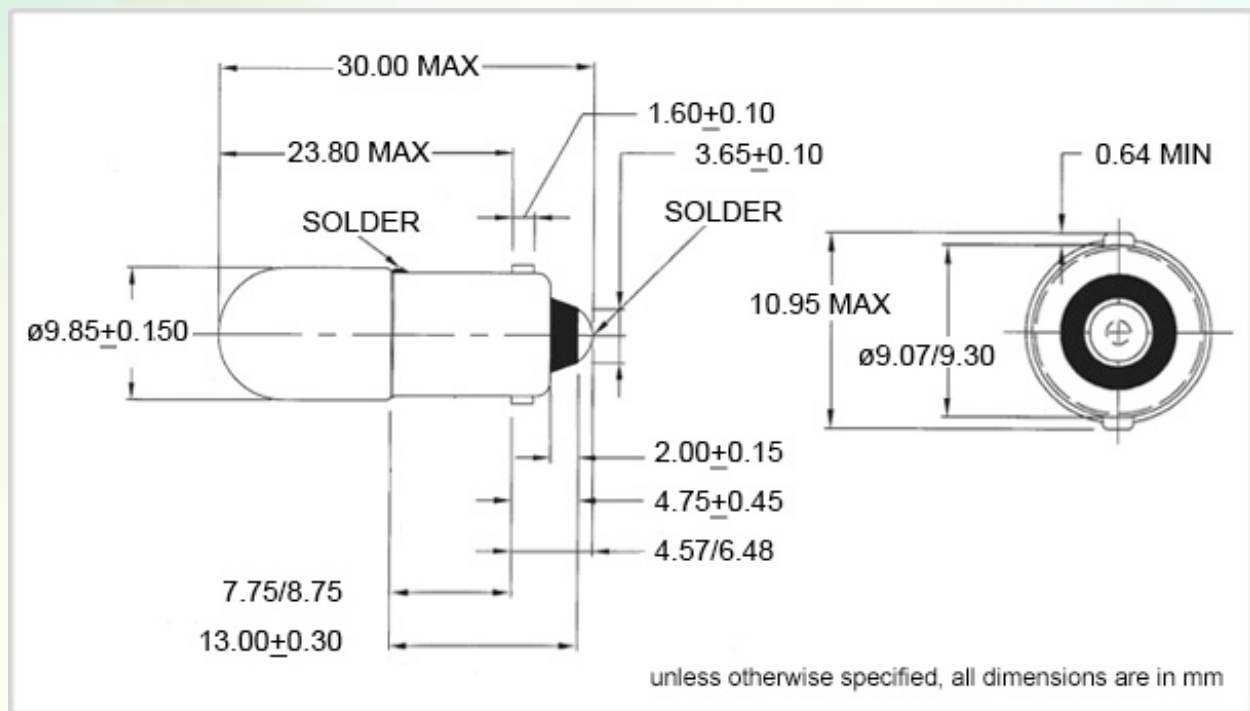

NOTES

1. LCL = .63" (16mm)
2. Nickel-plated brass construction base
3. Part mark WL-1813
4. RoHS compliant
5. ANSI trade number 1813

