


T-3¼ MINIATURE BAYONET BASE

MINIATURE LAMP

28V 40mA

WAMCO PART NO.		ENVELOPE SIZE		BASE TYPE	RATING		FILAMENT SHAPE	
WL-1819		T-3¼		BA9s	28V 40mA		C-2F	
TEST VOLTS	CURRENT (A)				LIGHT OUTPUT (MSCP)			LIFE HRS
	MIN	NOM	MAX	MIN	NOM	MAX		
	28V	36	40	44	.272	.340	.408	
								2,500

DIMENSIONAL CHARACTERISTICS

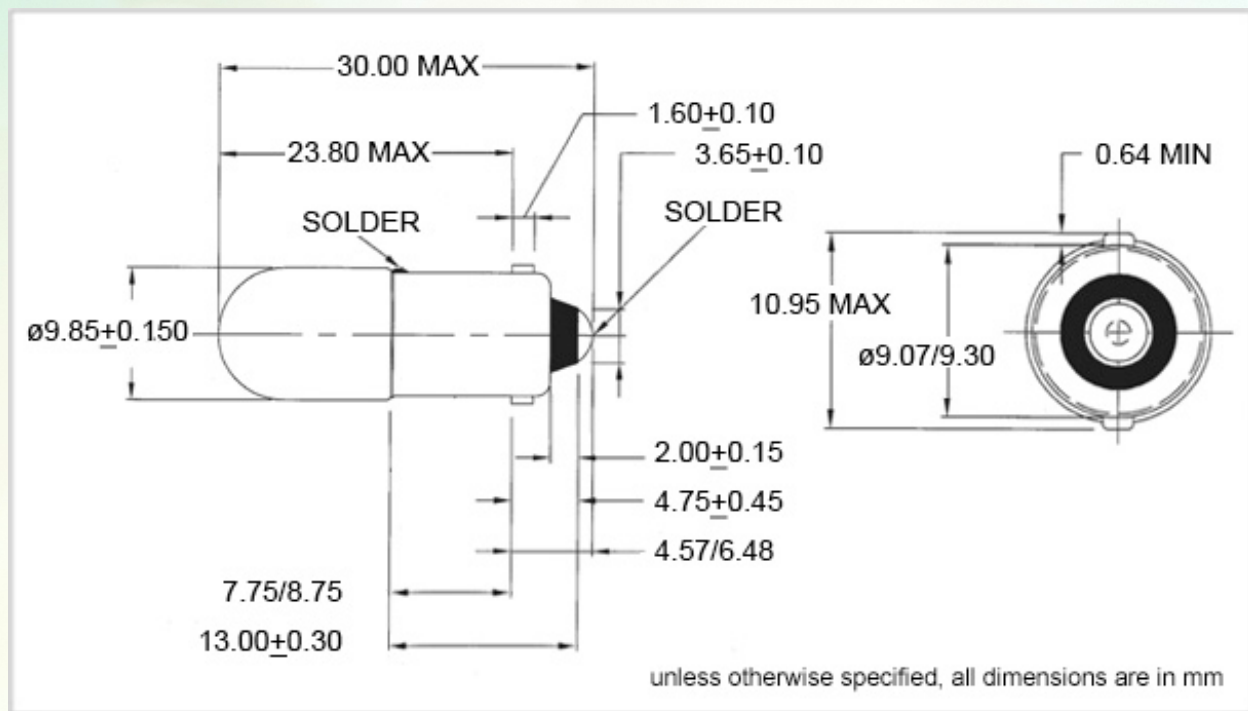

NOTES

1. LCL = .63" (16mm)
2. Nickel-plated brass construction base
3. Part mark WL-1819
4. RoHS compliant
5. ANSI trade number 1819
6. Military standard MS25231-1819

