


T-3¼ MINIATURE BAYONET BASE

MINIATURE LAMP

36V .10A

WAMCO PART NO.		ENVELOPE SIZE		BASE TYPE	RATING		FILAMENT SHAPE	
WL-1822		T-3¼		BA9s	36V .10A		C-2F	
TEST VOLTS	CURRENT (A)			LIGHT OUTPUT (MSCP)				LIFE HRS
	MIN	NOM	MAX	MIN	NOM	MAX		
	36V	.090	.100	.110	1.57	2.10	2.63	
							1,000	

DIMENSIONAL CHARACTERISTICS

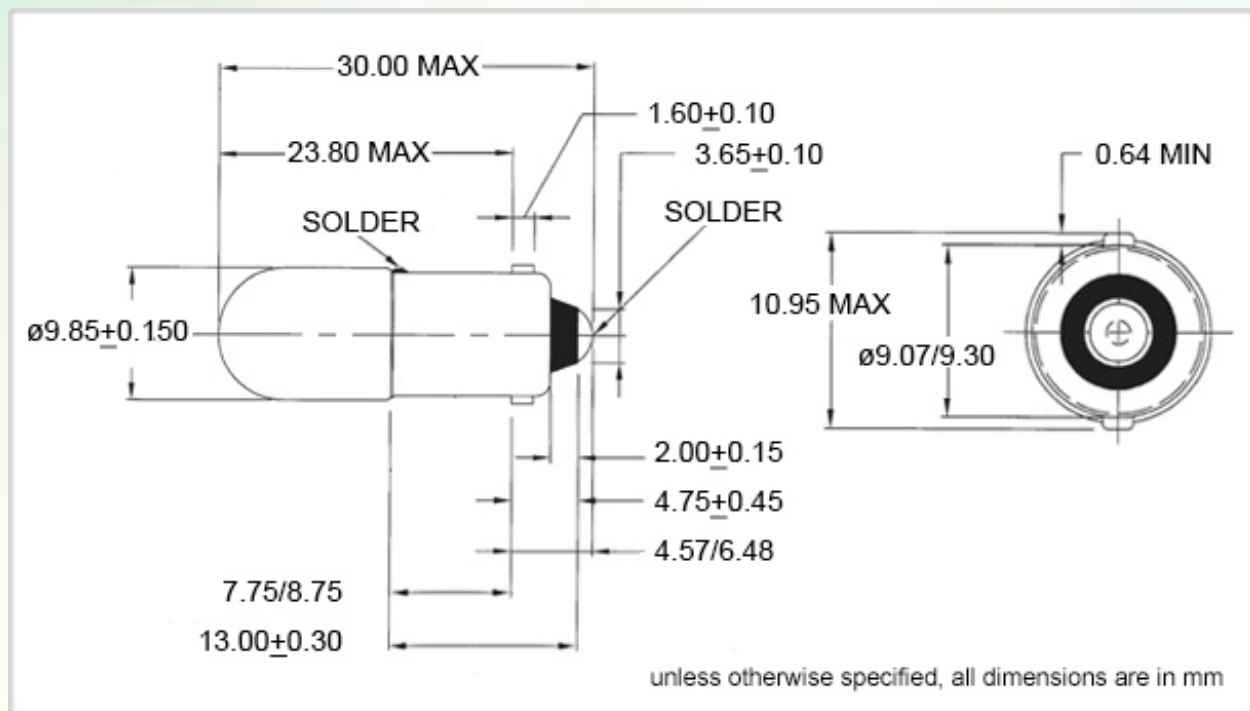

NOTES

1. LCL = .63" (16mm)
2. Nickel-plated brass construction base
3. Part mark WL-1822
4. RoHS compliant
5. ANSI trade number 1822

