


T-3¼ MINIATURE BAYONET BASE

MINIATURE LAMP

37.5V 50mA

WAMCO PART NO.		ENVELOPE SIZE	BASE TYPE	RATING	FILAMENT SHAPE		
WL-1828		T-3¼	BA9s	37.5V 50mA	C-2F		
TEST VOLTS	CURRENT (A)			LIGHT OUTPUT (MSCP)			LIFE HRS
	MIN	NOM	MAX	MIN	NOM	MAX	
37.5V	45	50	55	.487	.650	.813	3,000

DIMENSIONAL CHARACTERISTICS

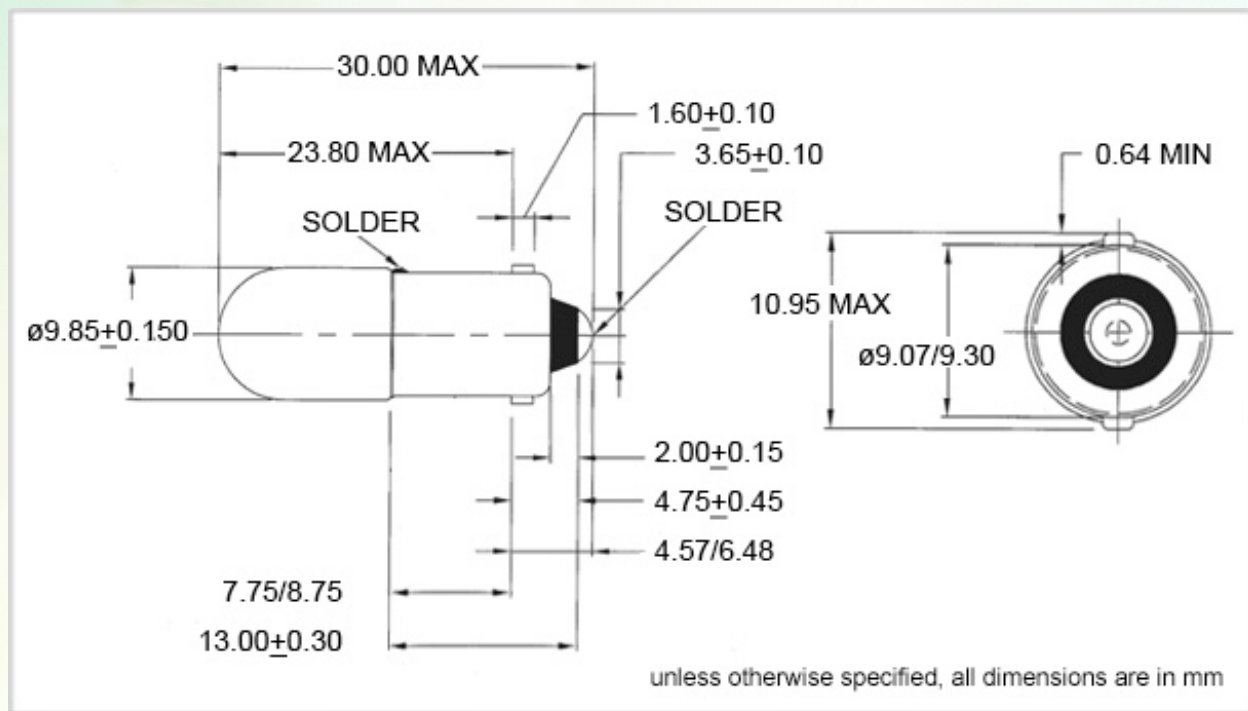

NOTES

1. LCL = .63" (16mm)
2. Nickel-plated brass construction base
3. Part mark WL-1828
4. RoHS compliant
5. ANSI trade number 1828

