


T-3¼ MINIATURE BAYONET BASE

MINIATURE LAMP

28V .20A

WAMCO PART NO.		ENVELOPE SIZE		BASE TYPE	RATING		FILAMENT SHAPE	
WL-1873		T-3¼		BA9s	28V .20A		C-2F	
TEST VOLTS	CURRENT (A)			LIGHT OUTPUT (MSCP)				LIFE HRS
	MIN	NOM	MAX	MIN	NOM	MAX		
	28V	.180	.200	.220	2.25	3.00	3.75	
							7,000	

DIMENSIONAL CHARACTERISTICS

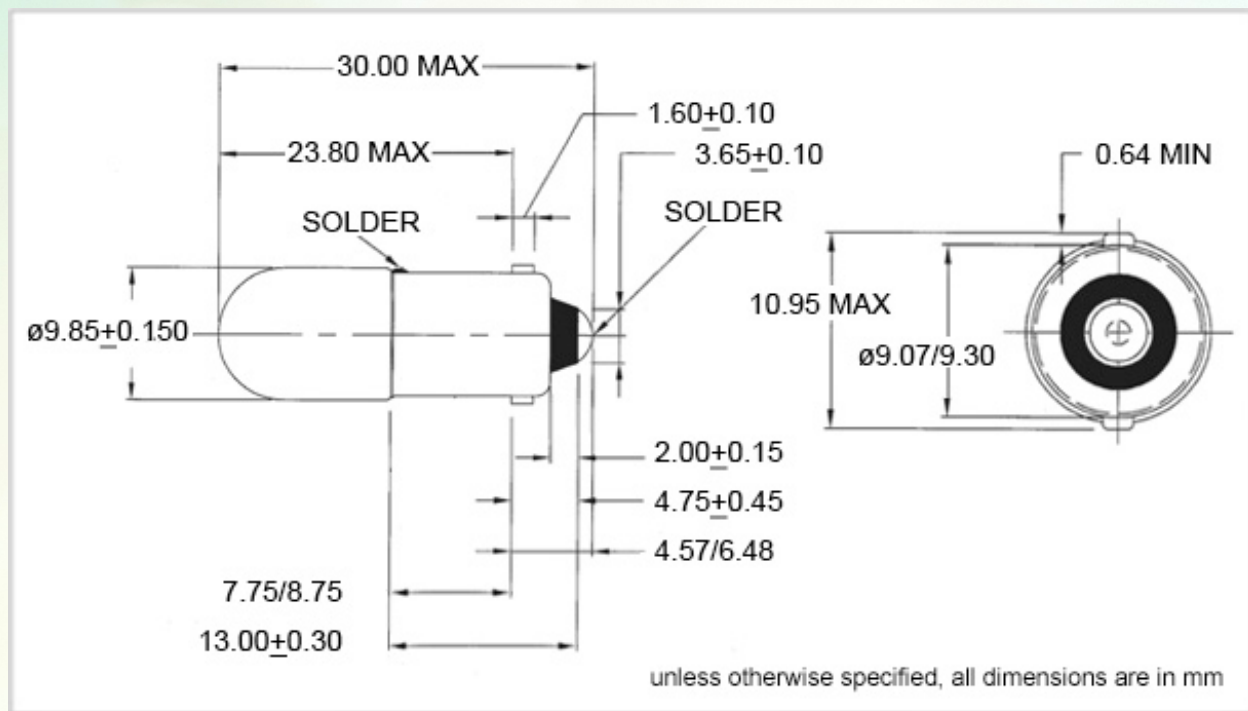

NOTES

1. LCL = .63" (16mm)
2. Nickel-plated brass construction base
3. Part mark WL-1873
4. RoHS compliant
5. ANSI trade number 1873
6. Military standard MS25231-1873

