


T-3¼ MINIATURE BAYONET BASE

MINIATURE LAMP

28V .20A

WAMCO PART NO.		ENVELOPE SIZE		BASE TYPE		RATING		FILAMENT SHAPE	
WL-1873F		T-3¼		BA9s		28V .20A		C-2F	
TEST VOLTS	CURRENT (A)			MIN	LIGHT OUTPUT (MSCP)		MAX	LIFE HRS	
	MIN	NOM	MAX		NOM				
28V	.180	.200	.220	—	NOT RATED		—	7,000	

DIMENSIONAL CHARACTERISTICS

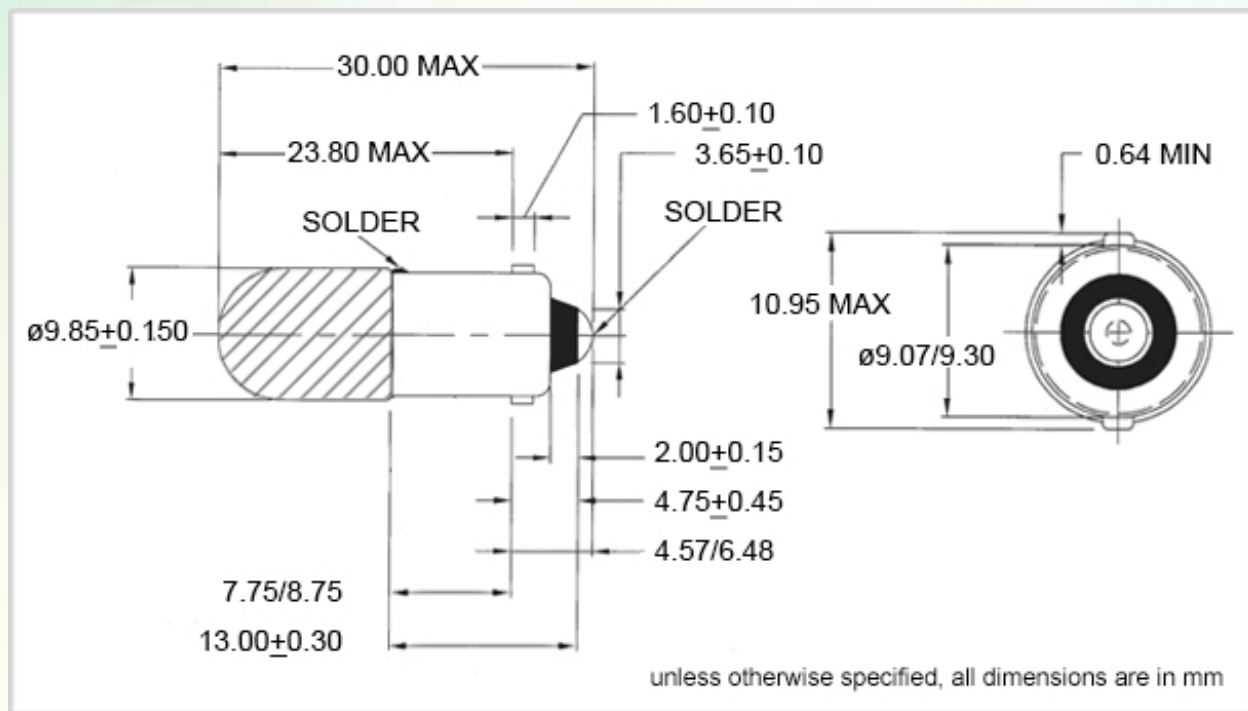

NOTES

1. LCL = .78" (19.4mm)
2. Nickel-plated brass construction base
3. Frosted envelope
4. Part mark WL-1873F
5. RoHS compliant
6. ANSI trade number 1873 F

