


T-3¼ MINIATURE BAYONET BASE

MINIATURE LAMP

14V .24A

WAMCO PART NO.	ENVELOPE SIZE	BASE TYPE	RATING	FILAMENT SHAPE			
WL-1891	T-3¼	BA9s	14V .24A	C-2F			
TEST VOLTS	CURRENT (A)			LIGHT OUTPUT (MSCP)			LIFE HRS
	MIN	NOM	MAX	MIN	NOM	MAX	
14V	.216	.240	.264	1.5	2.0	2.5	500

DIMENSIONAL CHARACTERISTICS

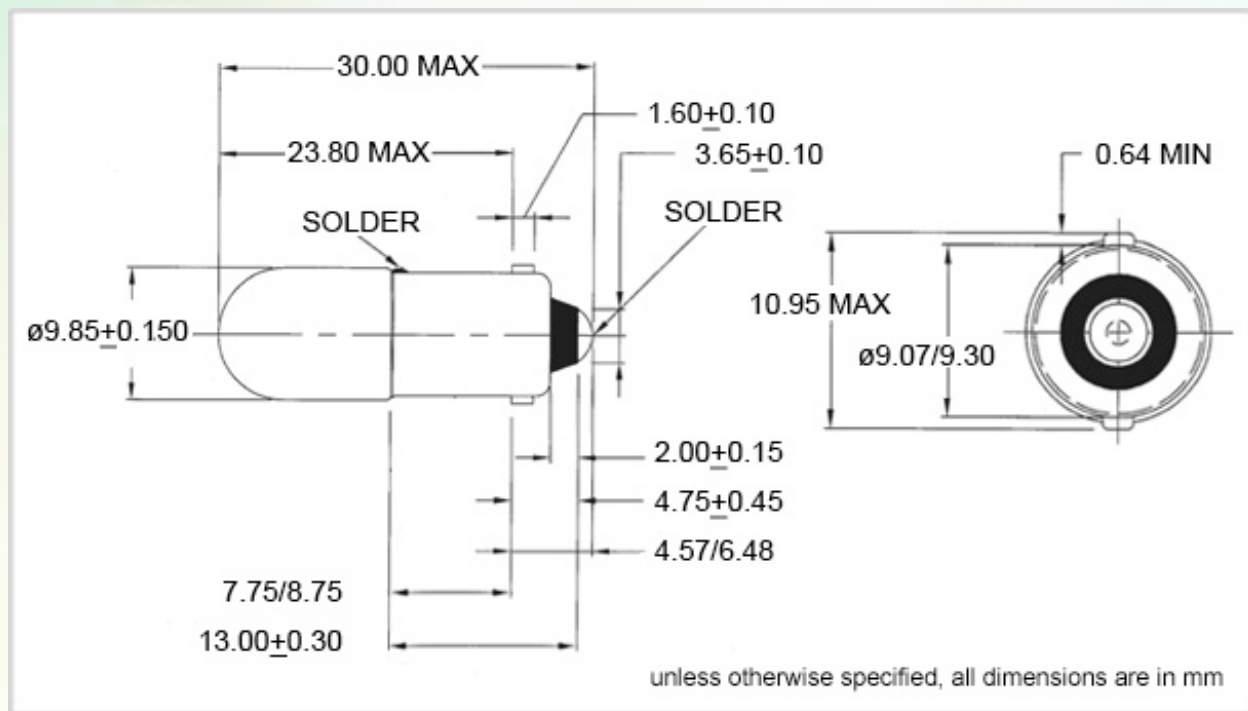

NOTES

1. LCL = .63" (16mm)
2. Nickel-plated brass construction base
3. Part mark WL-1891
4. RoHS compliant
5. ANSI trade number 1891

