


## Lamp Specification

Wamco Part No.	Envelope Size	Base Type	Rating	Filament Shape
WL-2233	S-8	BA15s	28V 0.766A	CC-8

Test Volts	Current (A)			Light Output (MSCP)			Life Hours
	Min.	Nom.	Max.	Min.	Nom.	Max.	
28.0	.689	.766	.843	16.8	21.0	25.2	2,000 Hrs

### Dimensional Characteristics:

1. L.C.L. = 1.19" (30.2mm)
2. Base = Nickel-plated Brass Construction.
3. Spiral Filament Supports.

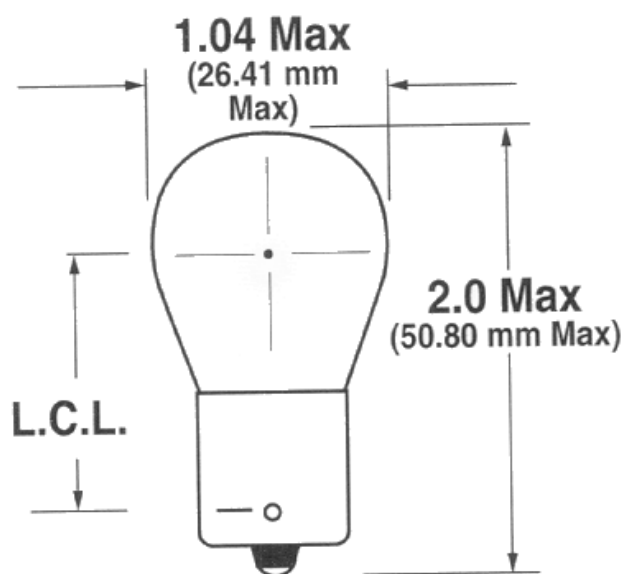

### Title:

**S-8 Single Contact Bayonet Base Lamp  
28V .766A Gas-Filled**

Drawn	3/7/00	CI	Notes: Unless otherwise specified, all dimensions are in inches.
Checked	3/7/00	EB	
Approved	3/7/00	EB	