


S-8 Double Contact Bayonet

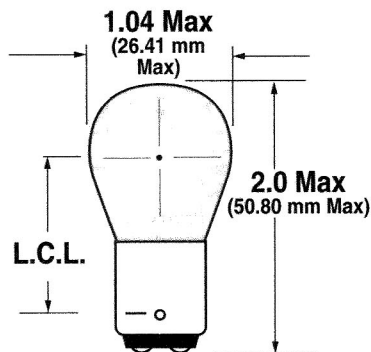

Line #	Part #	Volts	Amps	MSCP	Life	Filament	LCL
16	PL1492	2.50	1.500	3.200	15	S2	.94
17	PL1584	4.00	2.000	8.800	100	C2R	1.13
18	PL1612	5.40	1.860	10.000	1,000	C6	1.25
19	PL1594 #	6.00	5.000	36.000	250	C6	1.25
20	PL1130	6.40	2.630	21.000	200	C6	1.25
21	PL1158	6.40	2.630	21.000	200	C6	1.25
22	—	7.00	.750	3.000	1,000	C6	—
23	PL1618	6.40	2.630	21.000	200	C6	1.25
24	PL1608 *	6.40	2.690	21.000	200	C2V	1.25
25	PL6	6.40	3.000	23.000	500	C2R	1.25
26	PL1493 #	6.50	2.750	23.000	100	C6	1.13
27	PL1497	6.50	2.750	23.000	100	C6	1.13
28	PL88	6.80	1.910	15.000	300	C6	1.13
29	PL1648	8.00	2.100	21.000	200	C2R	—
30	PL8	8.00	2.200	20.000	500	C2R	1.25
31	PL94	12.80	1.040	15.000	700	C6	1.13
32	PL1005	12.80	1.310	21.000	300	2C2R	1.25
33	PL1176	12.80	1.340	21.000	300	C6	1.25
34	—	14.00	.590	6.000	1,500	C6	—
35	PL1152 #	12.80	1.340	21.000	500	C2R	1.25

Line #	Part #	Volts	Amps	MSCP	Life	Filament	LCL
1	PL1142	12.80	1.440	21.000	1,000	C6	1.25
2	PL1076	12.80	1.800	32.000	200	C6	1.25
3	PL1696	28.00	.420	10.000	500	C2V	1.25
4	PL306	28.00	.510	15.000	300	C2V	1.13
5	PL1692	28.00	.610	15.000	1,000	2C2R	1.13
6	PL1666	28.00	.630	21.000	300	2CC6	1.25
7	PL308	28.00	.670	21.000	300	C2V	1.13
8	PL1204	28.00	.710	21.000	400	C2V	1.25
9	PL1231W	28.00	.750	21.000	150	CC6	1.25
10	PL1638	28.00	1.020	32.000	500	2C6	1.25
11	PL1228	34.00	.450	15.000	150	C2V	1.13
12	PL1229	40.00	.380	15.000	400	C2V	1.13
13	PL110	44.00	.170	6.000	200	C7A	1.13
14	PL1676	45.50	.220	7.600	1,000	C13	1.13

* Silver contacts

Bulb selected for minimum imperfections