


S-8 SINGLE CONTACT BAYONET BASE

MINIATURE LAMP

28V 0.670A

WAMCO PART NO.		ENVELOPE SIZE		BASE TYPE	RATING		FILAMENT SHAPE	
WL-307SB		S-8		BA15s	28V 0.670A		C-2V	
TEST VOLTS	CURRENT (A)			MIN	LIGHT OUTPUT (MSCP) [1]		LIFE HRS	
	MIN	NOM	MAX		NOM	MAX		
28V	.603	.670	.737	—	21.0 [REF]	—	300	

DIMENSIONAL CHARACTERISTICS

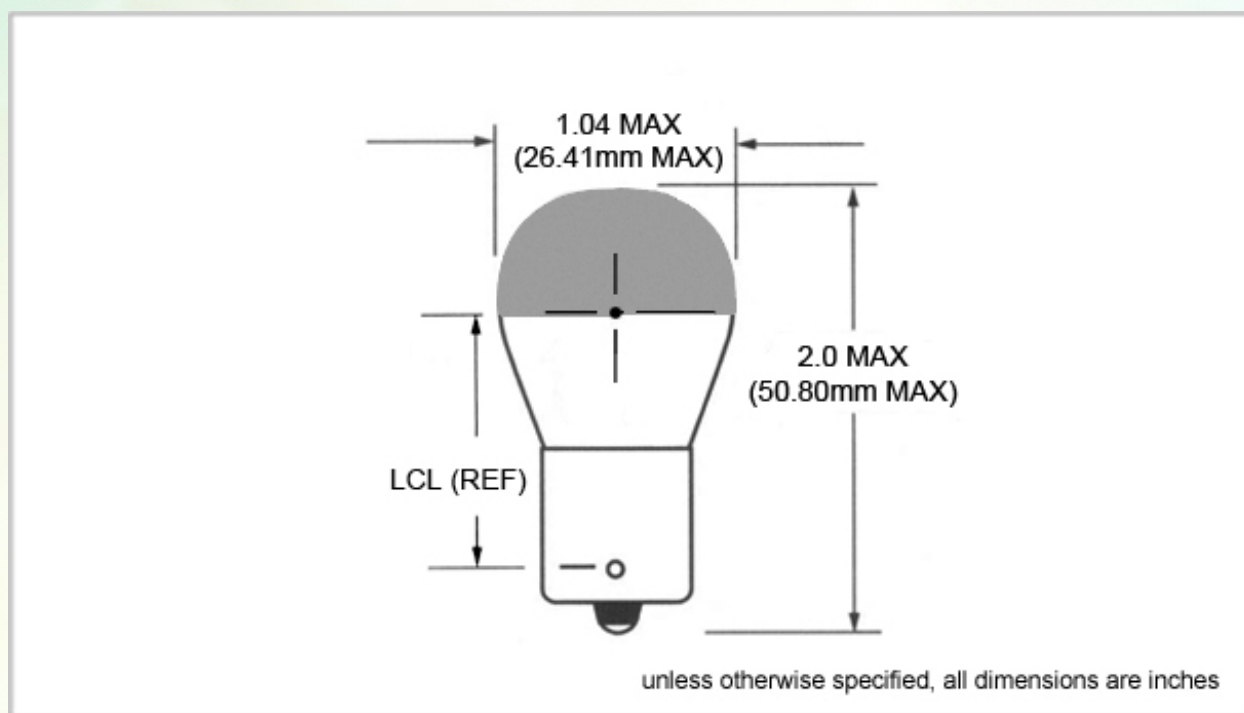

NOTES

1. MSCP prior to coating
2. LCL = 1.13" (28.7mm)
3. Nickel-plated brass construction base
4. Silver bowl; bottom edge of coated area to top of bayonet pins to be approximately equal to the LCL dimension
5. Part mark WL-307SB
6. RoHS compliant
7. ANSI trade number 307 SB

