

S-8 DOUBLE CONTACT BAYONET BASE

MINIATURE LAMP

28V 0.670A

WAMCO PART NO.

WL-308IF

ENVELOPE SIZE

S-8

BASE TYPE

BA15d

RATING

28V 0.670A

FILAMENT SHAPE

C-2V

TEST VOLTS

28V

MIN

.603

CURRENT (A)

NOM

.670

MAX

.737

MIN

-

LIGHT OUTPUT (MSCP)

NOM

NOT RATED


MAX

-

LIFE HRS

300

DIMENSIONAL CHARACTERISTICS

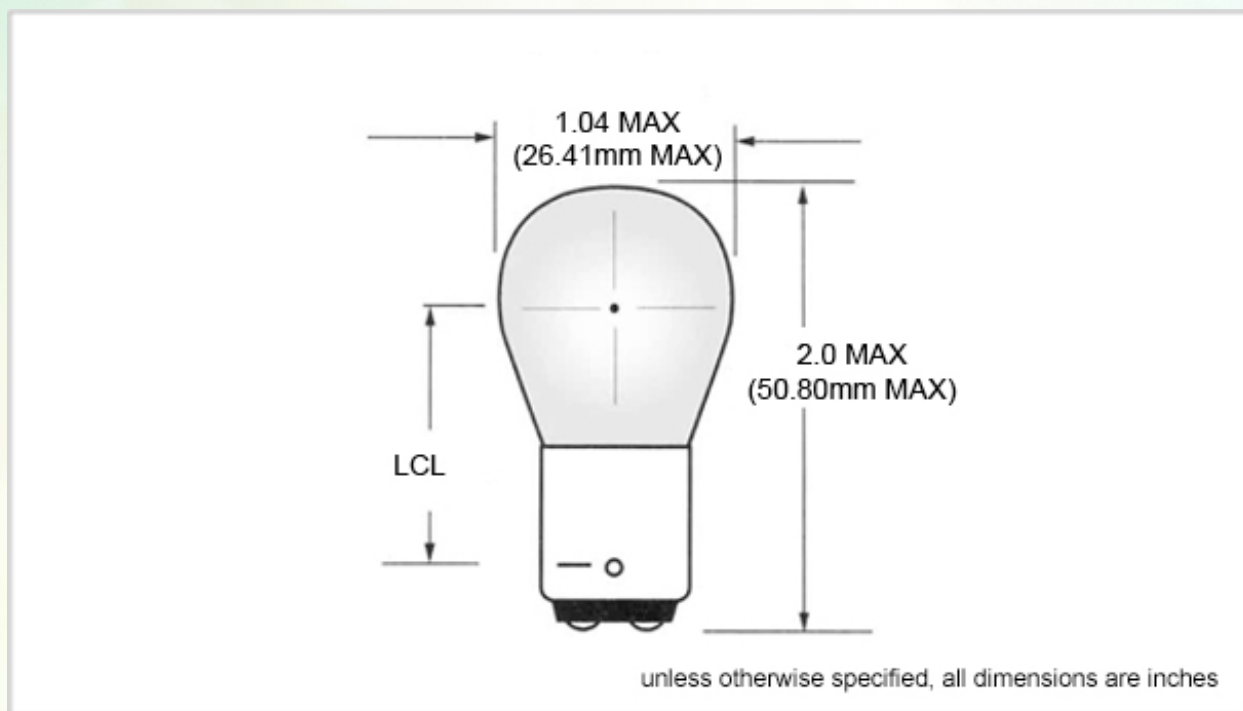

NOTES

1. LCL = 1.13" (28.7mm)
2. Nickel-plated brass construction base
3. Frosted envelope
4. Part mark WL-308IF
5. RoHS compliant
6. ANSI trade number 308 IF

