


T-3¼ MINIATURE BAYONET BASE

MINIATURE LAMP

28V .17A

WAMCO PART NO.		ENVELOPE SIZE		BASE TYPE	RATING		FILAMENT SHAPE	
WL-313R		T-3¼		BA9s	28V .17A		C-2F	
TEST VOLTS	CURRENT (A)			LIGHT OUTPUT (MSCP) ⁽¹⁾			LIFE HRS	
	MIN	NOM	MAX	MIN	NOM	MAX		
	28V	.153	.170	.187	2.45	3.50		4.55

DIMENSIONAL CHARACTERISTICS

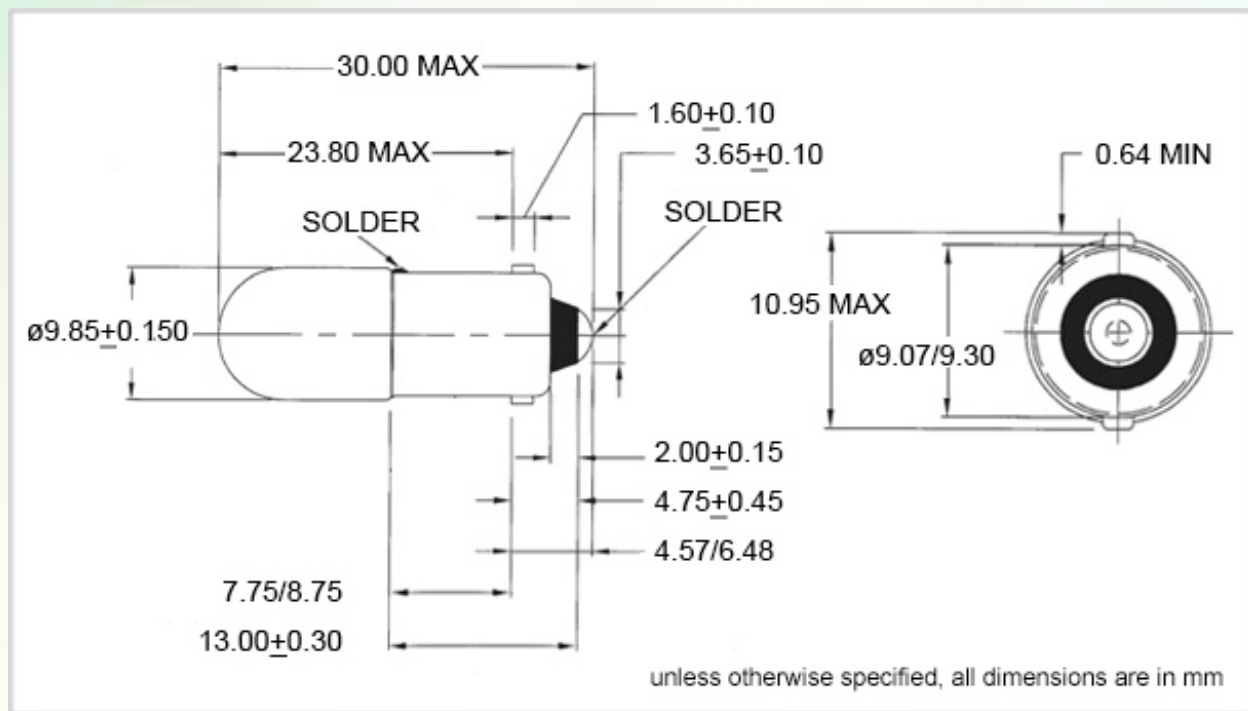

NOTES

1. MSCP rating is for the clear lamp prior to coating
2. LCL = .63" (16mm)
3. Nickel-plated brass construction base
4. Envelope coated red
5. Part mark WL-313R
6. RoHS compliant
7. ANSI trade number 313 R

