


T-1^{3/4} Midget Flanged

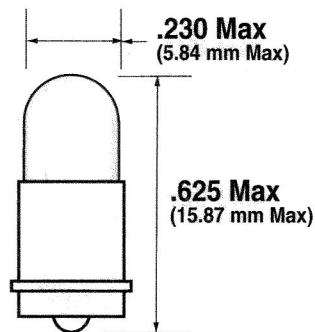

Line #	Part #	Volts	Amps	MSCP	Life	Filament
40	PL331	1.35	.060	.010	500	C2R
41	PL251	2.47	.300	.450	30	C2R
42	PL368	2.50	.200	.220	500	C2R
43	PL268	2.50	.350	.200	10,000	C2R
44	PL343	2.50	.400	.550	30	C2R
45	PL338	2.70	.060	.040	6,000	C2R
46	PL375	3.00	.015	.003	10,000	C6
47	PL7329	3.00	.030	.020	1,800	C6
48	PL7331	4.50	.120	.050	25,000	C2R
49	PL8950	5.00	.017	.018	8,000	C2R
50	PL7332	5.00	.060	.030	60,000	C2R
51	PL7333	5.00	.060	.050	25,000	C2R
52	PL3150	5.00	.060	.150	5,000	C2R
53	PL7335	5.00	.115	.150	40,000	C2R
54	PL7334	5.00	.190	.450	1,000	C2R
55	PL345	6.00	.040	.030	10,000	C2V
56	PL7336	6.00	.200	.100	50,000	C2F
57	PL328	6.00	.200	.600	1,000	C2R
58	PL7337	6.00	.220	.630	3,000	C2R
59	PL380	6.30	.040	.020	20,000	C2V
60	PL377	6.30	.075	.230	1,000	C2R
61	PL350	6.30	.150	.450	3,000	C2R
62	PL381	6.30	.200	.400	20,000	C2F
63	PL349	6.30	.200	.550	5,000	C2R
64	PL344	10.00	.014	.002	50,000	C2F
65	PL367	10.00	.040	.080	5,000	C2F
66	PL7338	11.00	.022	.030	10,000	C2F
67	PL394	12.00	.040	.120	10,000	C2F
68	PL382	14.00	.080	.300	15,000	C2F
69	PL330	14.00	.080	.500	1,500	C2F

Line #	Part #	Volts	Amps	MSCP	Life	Filament
1	PL8918	14.00	.100	.500	10,000	C2F
2	PL370	18.00	.040	.150	10,000	C2F
3	PL459	22.00	.040	.300	2,000	C2F
4	PL8176	24.00	.050	.500	1,000	C2F
5	PL385	28.00	.040	.150	10,000	C2F
6	PL387	28.00	.040	.300	7,000	C2F
7	PL327	28.00	.040	.340	4,000	C2F
8	PL376	28.00	.060	.340	25,000	C2F
9	PL7341	28.00	.065	.650	5,000	C2F