


T-1¼ BI-PIN BASE

SUBMINIATURE LAMP

28V 40mA

WAMCO PART NO.		ENVELOPE SIZE	BASE TYPE	RATING	FILAMENT SHAPE		
WL-4009BPEGPL		T-1¼	BPE	28V 40mA	C-2F		
TEST VOLTS	CURRENT (mA)			LIGHT OUTPUT (MSCP)			LIFE HRS
	MIN	NOM	MAX	MIN	NOM	MAX	
28V	36	40	44	.225	.300	.375	7,000

DIMENSIONAL CHARACTERISTICS

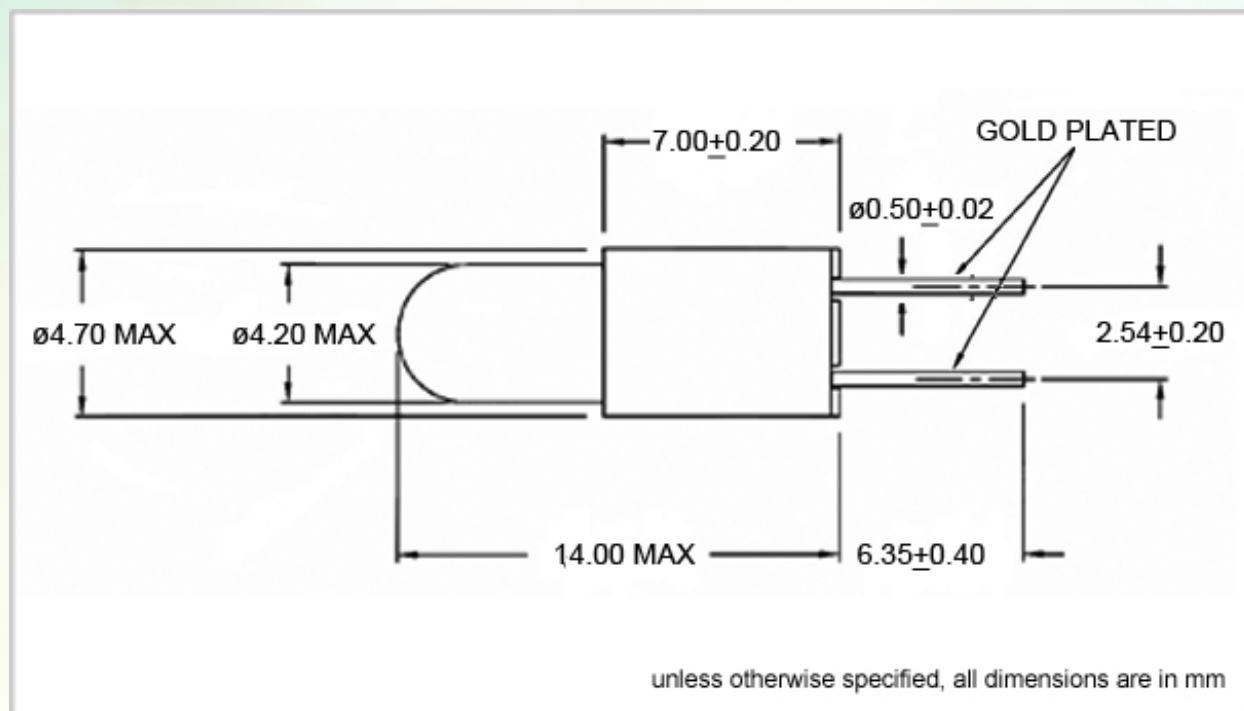

NOTES

1. Gold plated leads
2. Part mark WL-4009BPEGPL
3. RoHS compliant

