


G-4½ MINIATURE BAYONET BASE

MINIATURE LAMP

7V .41A

WAMCO PART NO.		ENVELOPE SIZE		BASE TYPE	RATING		FILAMENT SHAPE	
WL-55		G-4½		BA9s	7V .41A		C-2R	
		CURRENT (A)			LIGHT OUTPUT (MSCP)			
TEST VOLTS	MIN	NOM	MAX	MIN	NOM	MAX	LIFE HRS	
7V	.369	.410	.451	1.50	2.00	2.50	500	

DIMENSIONAL CHARACTERISTICS

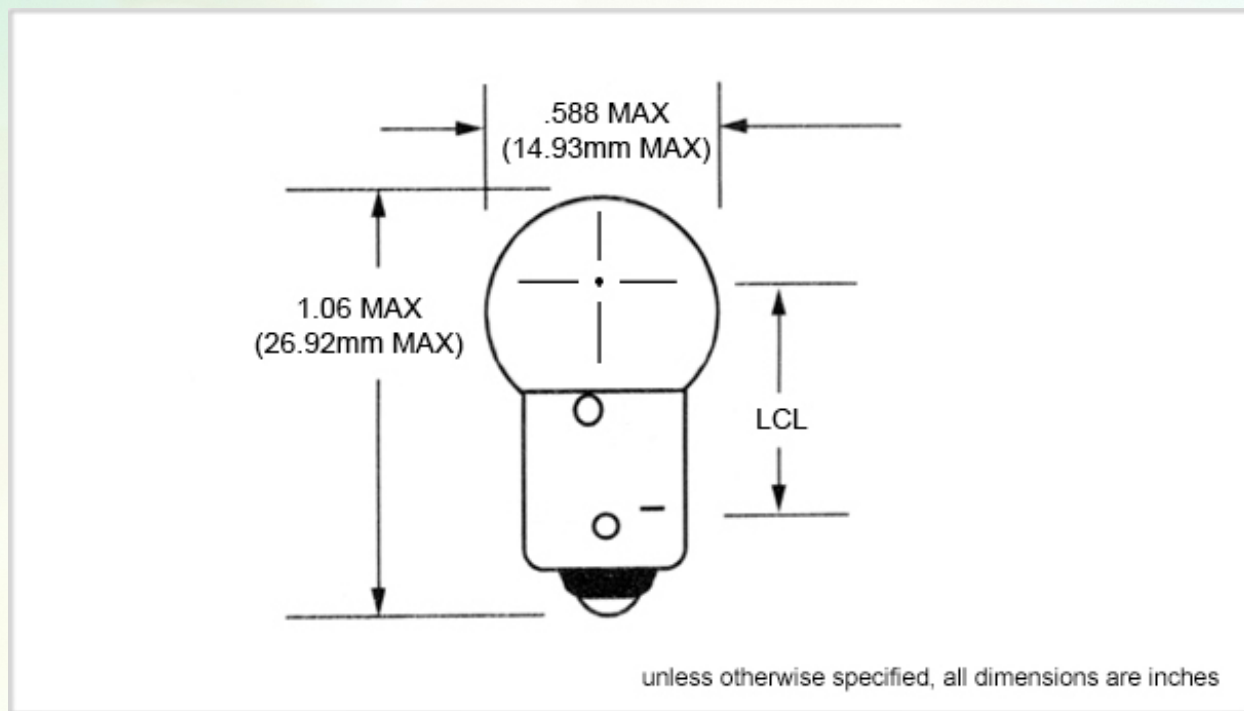

NOTES

1. LCL = .56" (14.2mm)
2. Nickel-plated brass construction base
3. Part mark WL-55
4. RoHS compliant
5. ANSI trade number 55

