


B-6 SILVER BOWL SINGLE CONTACT BAYONET BASE

GAS-FILLED LAMP

28V 15.7W

WAMCO PART NO.	ENVELOPE SIZE		BASE TYPE	RATING		FILAMENT SHAPE
WL-601-1	B-6		BA15s	28V 15.7W		CC-8
TEST VOLTS	CURRENT (A)			LIGHT OUTPUT (MSCP)		
	MIN	NOM	MAX	MIN	NOM	MAX
	28V	.504	.560	.616	12.8	16
						LIFE HRS
						2,000

DIMENSIONAL CHARACTERISTICS

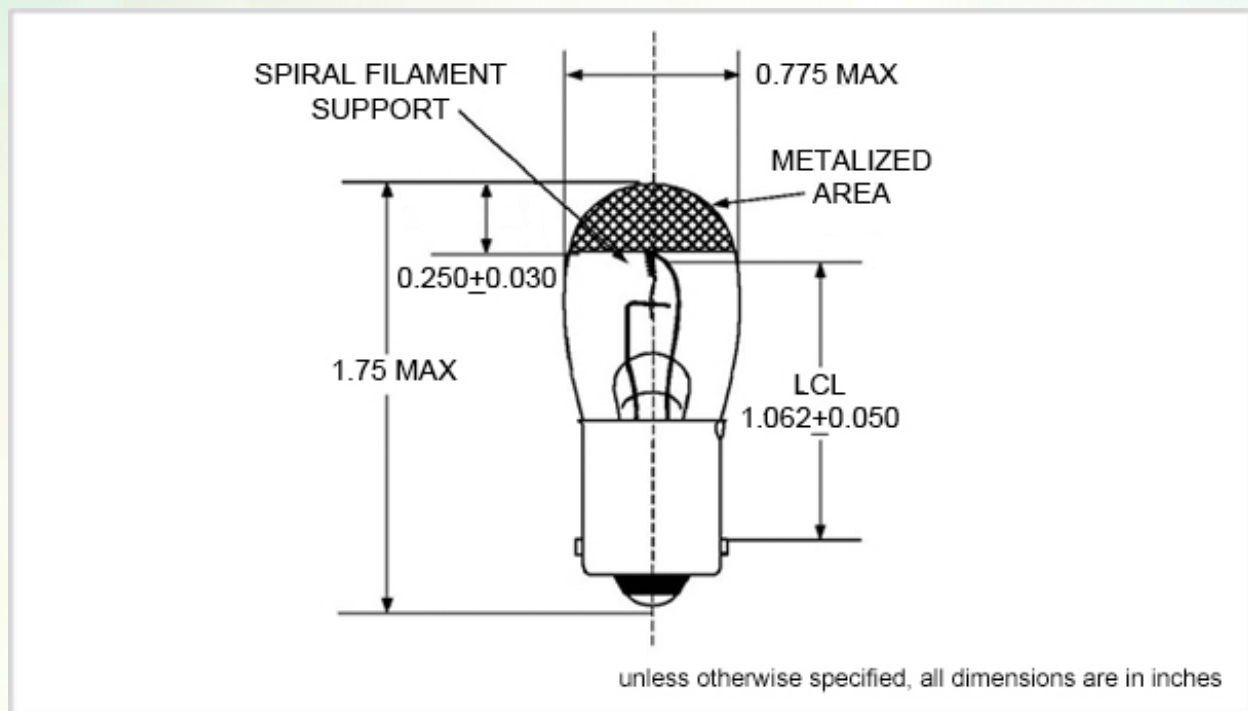

NOTES

1. Nickel-plated brass base
2. Spiral filament supports
3. MSCP rating is for clear bulb prior to metallization
4. Part mark WL-601-1
5. RoHS compliant

