


T-1 Sub-Midget Flanged

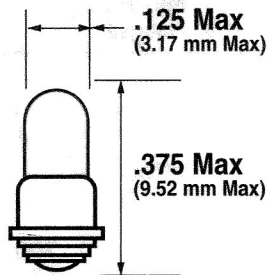

Line #	Part #	Volts	Amps	MSCP	Life	Filament
35	PL7244	1.25	.012	.004	1,000	C6
36	PL7245	1.35	.220	.020	25,000	C2R
37	PL7225	1.50	.010	.002	10,000	C6
38	PL7226	1.50	.015	.010	5,000	C2R
39	PL8102	1.50	.075	.030	16,000	C2R
40	PL7246	2.50	.015	.001	10,000	C2R
41	PL7247	2.50	.100	.100	10,000	C2R
42	PL7248	2.50	.320	.210	5,000	C2R
43	PL7249	3.00	.008	.001	16,000	C2R
44	PL679	3.00	.013	.001	10,000	C2R
45	PL7229	3.00	.015	.020	5,000	C2R
46	PL7231	3.00	.060	.030	100,000	C2R
47	PL7232	3.00	.120	.150	16,000	C2R
48	PL7233	5.00	.015	.020	10,000	C2V
49	PL8605	5.00	.017	.005	10,000	C2R
50	PL8022	5.00	.020	.034	10,000	C2R
51	PL7234	5.00	.030	.030	16,000	C2F
52	PL7250	5.00	.045	.040	10,000	C2R
53	PL682	5.00	.060	.030	60,000	C2R
54	PL685	5.00	.060	.050	25,000	C2R
55	PL6180	5.00	.060	.150	5,000	C2R
56	PL714	5.00	.075	.090	25,000	C2R
57	PL7235	5.00	.080	.150	3,000	C2R
58	PL718	5.00	.115	.150	40,000	C2R
59	PL7236	5.00	.115	.200	5,000	C2R
60	PL7239	5.00	.125	.250	5,000	C2R
61	PL7251	5.00	.145	.160	10,000	C2R
62	PL7240	10.00	.027	.100	10,000	C2F
63	PL32	12.00	.060	.150	16,000	C2F
64	PL8112	14.00	.065	.150	10,000	C2F
65	PL7241	18.00	.026	.150	10,000	C2F
66	PL124F	24.00	.025	.130	25,000	C2F
67	PL10431	28.00	.024	.130	16,000	C2F
68	PL6839	28.00	.024	.150	16,000	CC2F