


T-1 Bi-Pin

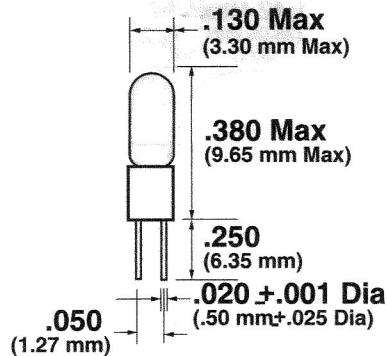

Line #	Part #	Volts	Amps	MSCP	Life	Filament
1	PL7252	1.25	.012	.004	1,000	C6
2	PL7253	1.35	.220	.020	25,000	C2R
3	PL3225	1.50	.010	.002	10,000	C6
4	PL7254	1.50	.015	.010	5,000	C2R
5	PL7255	1.50	.075	.030	16,000	C2R
6	PL7256	2.50	.015	.001	10,000	C2R
7	PL7732	2.50	.100	.100	10,000	C2R
8	PL7257	2.50	.320	.210	5,000	C2R
9	PL7258	3.00	.008	.001	16,000	C2R
10	PL7204P	3.00	.008	.010	16,000	C2R
11	PL7259	3.00	.013	.001	16,000	C2R
12	PL3229	3.00	.015	.020	5,000	C6
13	PL7260	3.00	.060	.030	100,000	C2R
14	PL7261	3.00	.120	.150	16,000	C2R
15	PL7209P	5.00	.015	.020	10,000	C2V
16	PL7262	5.00	.017	.005	10,000	C2R
17	PL7022	5.00	.021	.034	10,000	C2R
18	PL7263	5.00	.030	.030	16,000	C2R
19	PL7264	5.00	.045	.040	10,000	C2R
20	PL7680	5.00	.060	.030	60,000	C2R
21	PL7683	5.00	.060	.050	25,000	C2R
22	PL7265	5.00	.060	.150	5,000	C2R
23	PL7714	5.00	.075	.090	25,000	C2R
24	PL7266	5.00	.080	.150	3,000	C2R
25	PL7715	5.00	.115	.150	40,000	C2R
26	PL7267	5.00	.115	.200	5,000	C2R
27	PL7268	5.00	.125	.250	5,000	C2R
28	PL7269	5.00	.145	.160	10,000	C2R
29	PL8095	10.00	.027	.100	10,000	C2F
30	PL8097	12.00	.060	.150	16,000	C2F
31	PL8098	14.00	.065	.150	10,000	C2F
32	PL8099	18.00	.026	.150	10,000	C2F
33	PL124P	24.00	.025	.130	25,000	C2F
34	PL7839	28.00	.024	.150	16,000	CC2F