


GG-12B AIRCRAFT WARNING LAMP

SINGLE CONTACT INDEX BAYONET BASE

28V 40W

WAMCO PART NO.		ENVELOPE SIZE	BASE TYPE	RATING	FILAMENT SHAPE
WL-A-4174-24		GG-12B	BAY15s	28V 40W	CC-6
TEST VOLTS	CURRENT (A)			LIGHT DISTRIBUTION	LIFE HRS
	MIN	NOM	MAX		
28V	1.32	1.43	1.54	300 CANDLE POWER MINIMUM ON REFLECTOR AXIS HORIZONTAL AND VERTICAL BEAM SPREAD TO 150 CANDLE POWER, 40° MINIMUM	300

DIMENSIONAL CHARACTERISTICS

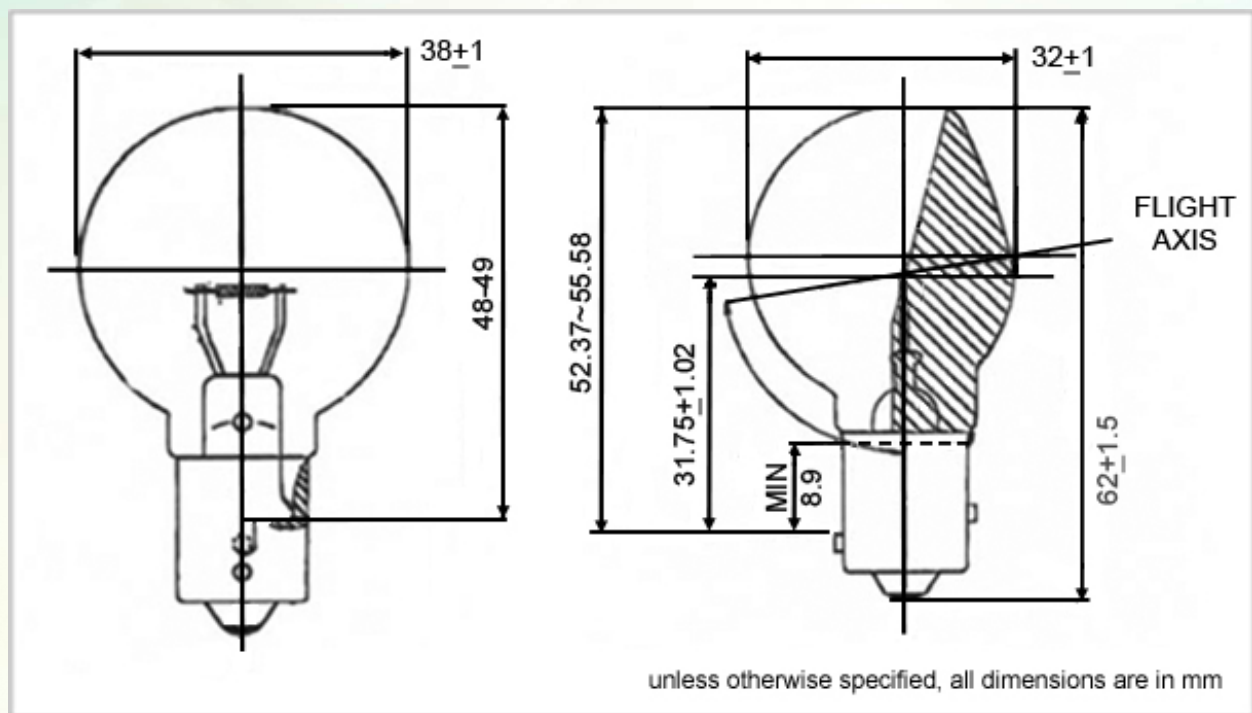

NOTES

1. Finish clear, except where reflective surface is required
2. Reflective coating must conform to the coating adhesion requirements of MIL-L-6363F, paragraph 4.6.6
3. Part mark WL-A-4174-24, 28V, 40W and M6363/3-1
4. RoHS compliant
5. ANSI trade number 4174
6. Military Standards M6363/3-1, MS24513-4174
7. QPL certified

