

Weller®

- Soldering Guns & Irons
- Table Top & Micro Torches

Weller® has been the leading brand in professional-quality soldering equipment since 1945. In addition to its famous irons and soldering guns, Weller is also recognized as a leader in advanced electronic rework and repair equipment and irons for sophisticated industrial applications, as well as numerous products for DIYers and hobbyists.

Weller® Soldering Table of Contents

Contents	Page No.
Soldering guns and kits	225 - 227
Soldering gun tips	227
Solid state soldering gun	227
Pro Series soldering iron	228
Marksman® soldering irons	228 - 231
Marksman® series tips	231 and 242
“ST” series tips	232 and 241
Therma-Boost heat tool	232
Therma-Boost tip kit	233
Battery powered soldering tools	233 - 234
Battery powered soldering tools tips	233 - 234
Butane powered soldering tools	235 - 238
Butane powered soldering tools tips	235 - 238
Butane fuel	238
Hobby and stained glass irons	239 - 240
“CT” series tips	240
Hobby and stained glass soldering stations	241 - 243
Heat guns and accessories	243
Weller numerical index	244

Standard Lightweight Gun Kit

- Single-heat gun produces 75 watts
- Ready to use in 15 seconds
- High efficiency tin-plated copper tip
- 2-wire cord
- Kit contains 7200 soldering gun, coil of lead free solder, 2 soldering tips and an instruction leaflet
- Packed in a clam shell
- UL and cUL listed
- 7 year warranty

See page 227 for soldering tip listing.



Cat No.	UPC No.	Description	Packed	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
7200PK	037103478801	Standard Soldering gun kit	Clamshell	75	120	6.0	2.71	3

Universal Gun and Kit

- Universal all-purpose gun
- Dual-heat gun produces 140 or 100 watts
- Pistol grip design
- Fingertip trigger selects high (1st trigger position) or low output (2nd trigger position)
- Ready to use in 6 seconds
- High efficiency, tin-plated copper tip
- Light illuminates work
- 2-wire cord
- Kit contains 8200 dual heat soldering gun, 1 soldering tip, 1 smoothing tip, 1 cutting tip, flux brush, soldering aid tool and a coil of lead free solder
- Instructions included
- UL and cUL listed
- 7 year warranty

See page 227 for soldering tip listing.



Cat No.	UPC No.	Description	Packed	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
8200PK	037103475862	Universal Soldering Gun Kit	Blow Molded Case	140/100	120	12	5.42	3
8200	037103475848	Universal Soldering gun	Box	140/100	120	8.8	3.95	3

Professional Gun and Kit



D550PK



D550

- Professional heavy-duty gun
- Dual-heat gun produces 260 or 200 watts
- Pistol grip design
- Fingertip trigger selects high (1st trigger position) or low output (2nd trigger position)
- Ready to use in 6 seconds
- Heavy gauge, high efficiency, tin-plated copper tip
- Twin lights illuminate work
- 2-wire cord
- Kit contains D550 soldering gun with 1 soldering tip, 1 smoothing tip, 1 cutting tip, flux brush, soldering aid tool and a coil of lead free solder
- Instructions booklet included
- UL and cUL listed
- 7 year warranty

See page 227 for soldering tip listing.

Cat No.	UPC No.	Description	Packed	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
D550PK	037103475428	Professional Soldering Gun Kit	Blow Molded Case	260/200	120	13	5.87	3
D550	037103475411	Professional Soldering Gun	Box	260/200	120	8.1	3.66	3

Industrial Gun and Kit



D650PK




D650

- Reliable industrial quality tool
- Heavy-duty dual-heat gun produces 300 or 200 watts
- Highest power output of all our soldering guns: 300 watts in high trigger (1st) position and 200 watts in low trigger (2nd) position
- Features nickel-plated copper secondary, heat-resistant thermoplastic housing
- 2-wire or grounded cord
- Nickel-plated copper tip
- Heavy-duty grounded cord
- Soldering, cutting and smoothing tips available
- Kit contains D650 soldering gun with one soldering tip and a coil of lead-free solder
- Instructions included
- UL and cUL listed
- 7 year warranty


See page 227 for soldering tip listing.

Cat No.	UPC No.	Description	Packed	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
D650	037103079480	Industrial Soldering Gun	Box	300/200	120	3.9	1.76	1
D650PK	037103129925	Industrial Soldering Gun Kit	Blow Molded Case	300/200	120	5	2.26	1

Replacement Tips for Soldering Guns

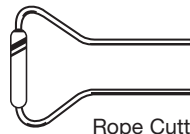


Rope Cutting tip

 

Iron Plated tip



 Cutting tip



Standard tip



Smoothing tip

- Tips compatible with Weller® soldering guns
- All tips are made of copper

Cat No.	UPC No.	Description	Gun(s)	Packed	Type	Pack Wt.		Shelf Pack
						lb	kg	
6110	037103475565	Tip With Hex Nut	8200(PK)	Bag	Cutting	0.25	0.11	6
6130	037103475589	Tip With Hex Nut	D550(PK)	Bag	Cutting	0.35	0.16	6
6150	037103480415	Tip Only	8200(PK)/D550(PK)	Bag	Cutting	0.20	0.09	6
6120	037103475572	Tip With Hex Nut	8200(PK)	Bag	Smoothing	0.25	0.11	6
6140	037103475596	Tip With Hex Nut	D550(PK)	Bag	Smoothing	0.30	0.14	6
6160	037103480422	Tip Only	8200(PK)/D550(PK)	Bag	Smoothing	0.21	0.09	6
7135W	037103475657	Tip Only-2 per Bag	8200(PK)	Bag	Standard	0.22	0.10	6
7235	037103478818	Tip Only-2 per Bag	7200PK	Bag	Standard	0.22	0.10	6
7250W	037103475718	Tip Only-2 per Bag	D550(PK)	Bag	Standard	0.21	0.09	6
7250N	037103475725	Tip With Hex Nut	D550(PK)	Bag	Standard	0.60	0.27	6
8125W	037103475824	Tip Only-2 per Bag	8200(PK)	Bag	Iron plated	0.18	0.08	6
8125N	037103475831	Tip With Hex Nut	8200(PK)	Bag	Iron plated	0.25	0.11	6
RCT	037103590237	Tip Only	8200(PK)/D550(PK)	Bag	Rope Cutting	0.16	0.07	6

Solid State Soldering Gun

- Interchangeable power heads control temperature
- Lightweight 7oz./198 g
- Ready to use in 6 seconds
- Slim, long-reach barrel
- Develops 600°F/315°C or 700°F/371°C
- UL and cUL listed



Cat No.	UPC No.	Description	Packed	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
GT7A	037103473202	Solid State Soldering Gun, 700°F	Box	150	120	5.3	2.37	6
GT7A3	037103473219	Solid State Soldering Gun, 700°F, 3-Wire Cord	Box	150	120	5.3	2.37	6
7A	037103473196	Power Head, 3/16" Chisel, 700°F	Card	-	-	0.179	0.08	6
6B	037103472830	Power Head, 1/8" Cone, 600°F	Card	-	-	0.179	0.08	6

Pro Series High Performance Soldering Iron

**NEW
PRODUCT**



WPS18MP

- Heats up to working temperature in just 35 seconds
- Patented design has performance equal to a 60 watt iron
- Red power-on LED changes to green when iron reaches working temperature
- LED work light illuminates working surface in low-light conditions
- Co-molded grip for a comfortable feel
- Tool is designed to be self-standing; no stand is needed
- Tips use a modular jack and plug for easy tip exchange
- Ideal for hobbies, kits, radios, electrical, and electronics
- 7 year limited warranty
- UL and cUL listed

Cat No.	UPC No.	Description	Packed	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
WPS18MP	037103227348	Pro Series Lighted Soldering Iron	Card	18	12	0.95	0.43	4

Soldering Replacement Tips for WPS18MP Iron



WPS10



WPS11

**NEW
PRODUCT**

- Heater is contained in the tip for super-fast heat up
- Copper tip with long-life iron plating
- Nickel-chrome plating over the copper to prevent oxidation
- Iron plated working end is factory pre-tinned with lead free solder
- Modular jack plugs in to the body of the soldering tool quickly and easily

Cat No.	UPC No.	Description	Packed	Pack Wt.		Shelf Pack
				lb	kg	
WPS10	037103227355	Conical Replacement Tip for WPS18MP	Card	0.025	0.011	6
WPS11	037103227362	Chisel Replacement Tip for WPS18MP	Card	0.025	0.011	6

Marksman® Mini Iron (12 Watt)




See page 235 for soldering tip listing.

- Fine quality consumer mini iron
- 7"/178mm long
- Lightweight and pencil thin
- Ideal for fine soldering and hobby work such as electronic kits, model railways and jewelry making
- Replaceable nickel-plated copper tip
- Stainless steel barrel
- Heat and impact resistant handle
- UL Listed

Cat No.	UPC No.	Description	Packed	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
SP12	037103479716	Marksman Soldering Iron	Card	12	120	3.0	1.36	6

Marksman® Iron (25 Watt)

- Indicator light allows you to instantly see that the iron is on
- Fine quality consumer mini iron
- 8 1/4"/210mm long
- Featherweight iron with pencil handle
- Ideal for hobbies, kits, radios, and electronics work
- Includes MT1 1/8"/3mm diameter replaceable nickel-plated copper tip. Develops 750°F/400°C
- Stainless steel barrel and heat and impact resistant handle
- UL Listed. cUL Listed model available
- 7 year warranty

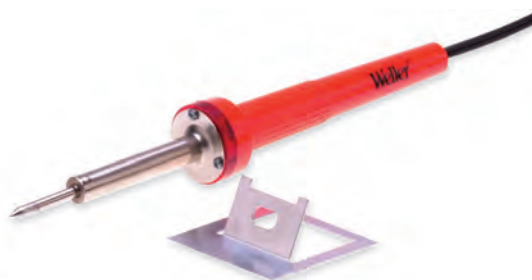

See page 235 for soldering tip listing.

Cat No.	UPC No.	Description	Packed	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
SP23L	037103169228	Marksman Lighted Soldering Iron	Card	25	120	5.1	2.31	6

Marksman® Iron Kit (25 Watt)

- Kit contains SP23L iron; MT1, MT2, MT3 1/8"/3mm diameter pre-tinned tips of nickel-plated copper; lead free solder and soldering aid tool
- Helpful hints and instructions inside clamshell
- UL Listed. cUL Listed model available
- 7 year warranty

See page 231 for soldering tip listing.



Cat No.	UPC No.	Description	Packed	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
SP23LK	037103169204	Marksman Lighted Soldering Iron Kit	Card	25	120	2.0	0.90	6

Marksman® Home Project Kit (25 Watt)

- Kit contains SP23L Iron, MT1, MT2, MT3, HK11 tips, and lead free solder
- Indicator light ring allows you to see that the iron is on
- Ideal for hobbies, kits, radios, electrical, and electronics
- Develops 750°F temperature
- Hot knife ideal for cutting rope or thin plastic sheet
- Stainless steel barrel and heat/impact resistant handle
- UL Listed. cUL Listed model available
- 7 year warranty

See page 231 for soldering tip listing.



Cat No.	UPC No.	Description	Packed	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
SP23LHPK	037103200600	Marksman Home Project Kit	Card	25	120	2.3	1.02	6

Marksman® Iron (40 Watt)



- Indicator light allows you to instantly see that the iron is on
- Fine quality consumer mini iron
- 8-1/4"/210mm long
- Lightweight pencil iron
- Ideal for hobbies
- MT10 1/4"/10mm diameter replaceable nickel-plated copper tip
- Develops 900°F/482°C
- Stainless steel barrel and heat and impact resistant handle
- UL Listed. cUL Listed model available
- 7 year warranty

See page 231 for soldering tip listing.

Cat No.	UPC No.	Description	Packed	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
SP40L	037103169181	Marksman Lighted Soldering Iron	Card	40	120	2.3	1.02	6

Marksman® Soldering Iron Kit (40 Watt)



- Kit contains SP40L iron; MT10, ST3, ST7 tips, lead free solder and soldering aid tool
- Indicator light allows you to see that the iron is on
- Ideal for electronics, electrical, hobbies, kits, etc.
- Develops 900° F temperature
- Stainless steel barrel and heat and impact resistant handle
- UL Listed. cUL Listed model available
- 7 year warranty

See page 231 for soldering tip listing.

Cat No.	UPC No.	Description	Packed	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
SP40LK	037103209269	Marksman Soldering Iron Kit	Card	40	120	1.4	0.64	3

Marksman® Iron (80 Watt)



- Indicator light allows you to instantly see that the iron is on
- Fine quality, consumer medium-duty iron
- 9 3/4"/247mm long
- Ideal for hobby work, stained glass and minor repairs
- Soldering iron rest included
- MTG20 3/8"/10mm diameter replaceable iron-plated copper tip
- Develops 900°F/482°C
- Stainless steel barrel and heat and impact resistant handle
- UL Listed. cUL Listed model available
- 7 year warranty

See page 231 for soldering tip listing.

Cat No.	UPC No.	Description	Packed	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
SP80L	037103169167	Marksman Lighted Soldering Iron	Card	80	120	3.0	1.36	6

Marksman® Iron (120 Watt)

- Fine quality, heavy-duty iron
- 11 3/8"/289mm long
- Ideal for home workshop, repairs, stained glass and hobbies
- Soldering iron rest included
- MTG30 1/2"/13mm diameter replaceable iron-plated copper tip
- Develops 900°F/482°C
- Stainless steel barrel and heat and impact resistant handle
- UL Listed. cUL Listed model available
- 7 year warranty



See page 231 for soldering tip listing.

Cat No.	UPC No.	Description	Packed	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
SP120	037103474537	Marksman Soldering Iron	Card	120	120	3.5	1.58	3

Marksman® Iron (175 Watt)

- Fine quality heavy duty consumer iron
- 12 1/2"/318mm long
- Extra heavy duty for demanding jobs like sheet metal work
- Soldering iron rest included
- MTG40 5/8"/16mm diameter replaceable iron-plated copper tip
- Develops 900°F/482°C
- Stainless steel barrel and heat and impact resistant handle
- UL Listed. cUL Listed model available
- 7 year warranty




See page 231 for soldering tip listing.

Cat No.	UPC No.	Description	Packed	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
SP175	037103474674	Marksman Soldering Iron	Card	175	120	4.0	1.81	3



Marksman® Series Tips

- Marksman® replacement tips
- Nickel-plated copper tips are available in a variety of styles
- MTG series tips are iron-plated for heavy-duty soldering irons
- Hanging bag for point-of-purchase display
- Packed 6 and 10 bags per carton

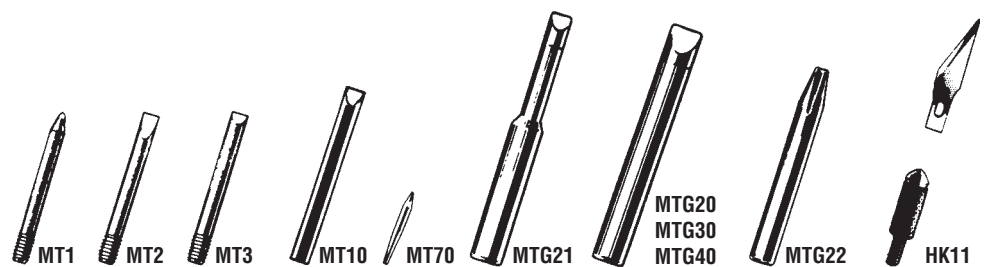

Cat No.	UPC No.	Description	Iron(s)	Packed	Type	Tip Size		Pack Wt.		Shelf Pack
						Inch	mm	lb	kg	
MT1	037103472175	Tip - 2/Bag	SP23L(K)	Bag	Cone	0.125	3	0.15	0.07	6
MT2	037103472410	Tip - 2/Bag	SP23L(K)	Bag	Screwdriver	0.125	3	0.18	0.08	6
MT3	037103472502	Tip - 2/Bag	SP23L(K)	Bag	Chisel	0.125	3	0.21	0.09	6
MT10	037103473615	Tip - 2/Bag	SP40L	Bag	Chisel	0.250	6	0.45	0.20	6
MT70	037103479808	Tip - 2/Bag	SP12	Bag	Cone	0.125	3	0.20	0.09	10
MTG20	037103476593	Tip - 1/Bag	SPG80L/WLC200	Bag	Chisel	0.375	10	0.73	0.33	6
MTG21	037103476609	Tip - 1/Bag	SPG80L/WLC200	Bag	Chisel	0.250	6	0.71	0.32	6
MTG22	037103479822	Tip, Glass Bead - 1/Bag	SPG80L/WLC200	Bag	Cone	0.375	10	0.70	0.32	6
MTG30	037103477903	Tip - 1/Bag	SP120	Bag	Chisel	0.500	13	0.80	0.36	6
MTG40	037103478672	Tip - 1/Bag	SP175	Bag	Chisel	0.625	16	0.30	0.14	6
HK11	037103473622	Tip, Blade and Chuck - 1/Bag	SP23L(K)	Bag	Hot Knife	0.125	3	0.19	0.08	6

“ST” Series Tips

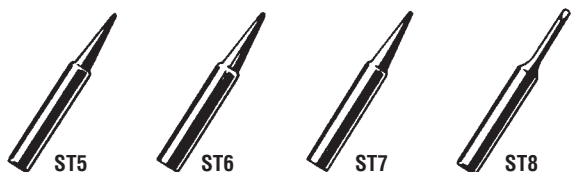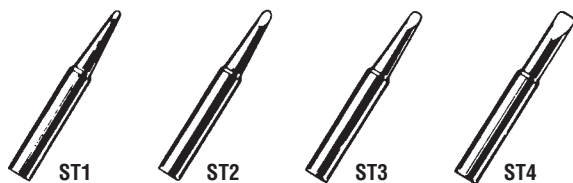

- Tips compatible with the SP40L (K) and WLC100 station
- Precision ground copper tips are plated with iron, nickel and chromium
- Tips are individually bagged and packed 10 per box.

Cat. No.	UPC No.	Use With	Packed	Type	Tip Size		Reach		Pack Wt.		Shelf Pack
					Inch	mm	Inch	mm	lb	kg	
ST1	037103472212	WP25/WP30/WP35	Bag	Screwdriver	0.063	1.60	0.750	19.1	0.25	0.11	10
ST2	037103472434	WP25/WP30/WP35	Bag	Screwdriver	0.093	2.40	0.750	19.1	0.25	0.11	10
ST3	037103472519	WP25/WP30/WP35	Bag	Screwdriver	0.125	3.20	0.750	19.1	0.25	0.11	10
ST4	037103472601	WP25/WP30/WP35	Bag	Screwdriver	0.188	4.70	0.750	19.1	0.25	0.11	10
ST5	037103472809	WP25/WP30/WP35	Bag	Single Flat	0.031	0.80	0.750	19.1	0.25	0.11	10
ST6	037103473189	WP25/WP30/WP35	Bag	Screwdriver	0.031	0.80	0.750	19.1	0.25	0.11	10
ST7	037103473394	WP25/WP30/WP35	Bag	Conical	0.031	0.80	0.750	19.1	0.25	0.11	10
ST8	037103473578	WP25/WP30/WP35	Bag	Narrow Screwdriver	0.062	1.60	0.750	19.1	0.25	0.11	10

Therma-Boost Heat Tool



- For a wide variety of jobs including soldering, cutting, smoothing, and shaping
- Therma-Boost trigger gives you added bursts of power when you need it
- 2 lights on the back of tool indicate standard or Therma-Boost modes
- Heats up to working temperature in just 45 seconds
- For continuous use. Therma-Boost mode can be used intermittently
- Ultra-lightweight - weighs just 3 oz.
- Kit includes heat tool, stand, 6 multi-use tips, and instructions
- Tips are for soldering, rope and foam cutting, smoothing, and scoring
- Tip changes are fast and easy
- UL and cUL listed

See page 233 for soldering tip listing.

Cat No.	UPC No.	Description	Temperature Range	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
TB100PK	037103211330	Therma-Boost Heat Tool	950° F/850° F	130 /30	120	3.13	1.42	5

Tip Kit for TB100PK Therma-Boost Heat Tool

Kit Contains:

Conical soldering tip
Rope cutting tip
Smoothing tip
Foam cutting tip
Scoring tip



Cat No.	UPC No.	Description	Packed	Pack Wt.		Shelf Pack
				lb	kg	
TB5TK	037103213655	Tip Kit for TB100PK Therma-Boost Heat Tool	Card	0.23	0.10	3

Battery Powered Soldering Iron Kit

- Heats up to working temperature in under 15 seconds
- Working temperature 900° F
- Red LED indicates when power is on
- Protective safety cap turns off power when placed on tool
- Over 120 intermittent solder joints with fresh batteries
- Perfect for field service repair on small parts and components
- Includes iron, tip, 3 AA batteries, lead free solder, and tip wrench

See below for soldering tip listing.



Cat No.	UPC No.	Description	Packed	Pack Wt.		Shelf Pack
				lb	kg	
BP645MP	037103210821	Battery Powered Soldering Iron Kit	Clamshell	2.05	0.93	5

Soldering Replacement Tip for BP645MP Iron

- Heater is contained in the tip for super-fast heat up
- Copper tip with long-life iron plating
- Nickel-chrome plating over the copper to prevent oxidation
- Iron plated working end is factory pre-tinned with lead free solder
- Modular jack plugs into the body of the soldering tool quickly and easily



Cat No.	UPC No.	Description	Packed	Pack Wt.		Shelf Pack
				lb	kg	
BP1	037103216830	Conical Soldering Replacement tip for BP645MP	Card	0.15	0.07	6

Pro Series Battery Powered Soldering Iron



- Heats up to working temperature in under 15 seconds
- Working temperature range 850° F/950° F
- White LED light illuminates working surface
- Dual power (hi/lo) indicated by red and green LEDs
- Co-molded grip for a comfortable feel
- Protective safety cap turns off power when placed on tool
- Over 150 intermittent solder joints with fresh batteries
- Perfect for field service repair on small parts and components
- Includes iron, 1 tip, 4 AA batteries, lead free solder, and tip wrench

See below for soldering tip listing.

Cat No.	UPC No.	Description	Packed	Pack Wt.		Shelf Pack
				lb	kg	
BP860MP	037103221551	Pro Series Battery Powered Soldering Iron	Clamshell	2.49	1.13	5

Replacement Soldering Tips for BP860MP Iron



BP10



BP11

- Heater is contained in the tip for super-fast heat up
- Copper tip with long-life iron plating
- Nickel-chrome plating over the copper to prevent oxidation
- Iron plated working end is factory pre-tinned with lead free solder
- Modular jack plugs into the body of the soldering tool quickly and easily

Cat No.	UPC No.	Description	Packed	Pack Wt.		Shelf Pack
				lb	kg	
BP10	037103221544	Conical Soldering Replacement tip for BP860MP	Card	0.15	0.07	6
BP11	037103221568	Chisel Soldering Replacement tip for BP860MP	Card	0.15	0.07	6

Butane Mini Soldering Iron with Piezo Ignition

- Piezo electronic ignition system for reliable ignition every time
- Adjustable gas flow valve controls temperature range
- Tip temperature 750° F / 900° F
- Up to 30 minutes continuous use on medium setting
- Refillable with Weller WB1 or WB2 filtered butane
- Also operates as a mini-torch when the tip is removed
- Window allows you to see fuel level
- Base allows tool to stand for hands free operation
- Safety cap can be replaced on tool for secure storage
- Use for soldering, heat shrink tubing, electrical, and electronics

See below for soldering tip listing.



Cat No.	UPC No.	Description	Packed	Pack Wt.		Shelf Pack
				lb	kg	
ML500MP	037103220912	Butane Mini Soldering Iron with Piezo Ignition	Clamshell	0.62	0.28	4

Replacement Soldering Tips for ML500MP Iron

- ML501: 0.06" (1.6 mm) conical replacement tip
- ML502: 0.09" (2.4 mm) conical replacement tip
- ML503: Use for cutting rope, foam, wax, stencils, etc.



ML501



ML502



ML503

Cat No.	UPC No.	Description	Packed	Pack Wt.		Shelf Pack
				lb	kg	
ML501	037103220929	Conical Replacement Soldering Tip for ML500MP	Card	0.18	0.08	6
ML502	037103220936	Chisel Style Replacement Soldering Tip for ML500MP	Card	0.18	0.08	6
ML503	037103220905	Knife Style Replacement Soldering Tip for ML500MP	Card	0.18	0.08	6

Portasol® Professional Self-igniting Kit and Tool



P2KC

- ESD safe to protect sensitive components
- A lightweight, compact cordless butane soldering and hot air tool for ultimate portability
- Piezo ignition with push-button ease and convenience - adjusts from 25 watts to 75 watts
- Fast heat-up for high productivity - melts solder in less than 40 seconds
- Gas capacity allows up to one hour of continuous use - ample for most jobs
- Refills in less than 20 seconds so you can stay on the job
- Automatic cut-off switch when cap replaced for safety
- Can be used as a mini-torch with optional PPT12 flame tip
- Interchangeable soldering tips and hot air accessories screw on quickly and easily
- Soldering tips are iron plated for long life
- P2KC kit contains Portasol® P2C soldering tool, PPT9 hot air tip, PPT10 hot knife tip, PPT11 hot air deflector for heat shrink tubing, PPT12 flame tip, sponge and tray, tool holder, and operating instructions

See page 237 for soldering tip listing.

Cat No.	UPC No.	Brand	Description	Packed	Pack Wt.		Shelf Pack
					lb	kg	
P2KC	037103169372	Weller/Portasol	Professional Self-igniting Cordless Butane Soldering Iron Kit	Card	0.4	0.18	1
P2C	037103169389	Weller/Portasol	Professional Self-igniting Cordless Butane Soldering Iron	Card	0.2	0.10	1

Portasol® is a registered trademark of Oglesby and Butler Limited.

Portasol® Super-Pro Self-igniting Kit and Tool

Weller



PSI100K


- Self-igniting portable butane heat tool - professional quality
- Ideal for service technicians for such uses as anti-static soldering, heat shrink and cutting rope
- Features "Auto Switch" safety shut-off, iron plated tips, and built-in butane filter
- Butane fuel level is visible through a window on the body of the tool
- Rugged stainless-steel body provides up to 125 watts of power
- Adjustable temperature up to 1,076°F
- Operates up to 2 hours per refill
- Refills with butane fuel - Weller® cat no. WB1 or WB2
- Kit contains PSI100 iron, sponge, stand and extra tips packed in a plastic case

See page 237 for soldering tip listing.

Cat No.	UPC No.	Brand	Description	Packed	Pack Wt.		Shelf Pack
					lb	kg	
PSI100K	037103060976	Weller/Portasol	Super-Pro Self-igniting Cordless Butane Soldering Iron Kit	Box	1.3	0.59	1
PSI100C	037103127174	Weller/Portasol	Super-Pro Self-igniting Cordless Butane Soldering Iron	Card	0.3	0.14	1

Portasol® is a registered trademark of Oglesby and Butler Limited.

Tips for Weller®/Portasol® Cordless Butane Soldering Irons

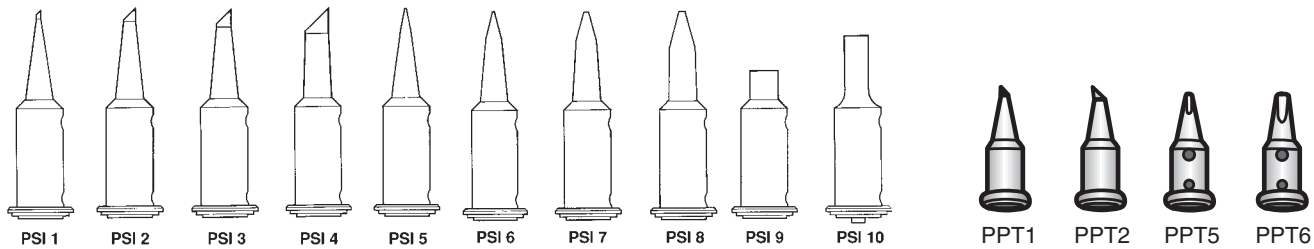

Cat. No.	UPC No.	Use With	Packed	Type	Tip Size		Pack Wt.		Shelf Pack
					Inch	mm	lb	kg	
PPT1	037103183620	P2C/P2KC	Bag	Single Flat	0.031	0.80	0.07	0.03	5
PPT2	037103183637	P2C/P2KC	Bag	Single Flat	0.094	2.40	0.07	0.03	5
PPT5	037103183668	P2C/P2KC	Bag	Double Flat	0.031	0.80	0.70	0.32	5
PPT6	037103183675	P2C/P2KC	Bag	Double Flat	0.094	2.40	0.70	0.32	5
PSI1	037103062666	PSI100	Card	Single Flat	0.031	1.00	0.20	0.09	5
PSI2	037103062659	PSI100	Card	Single Flat	0.094	2.40	0.20	0.09	5
PSI3	037103062628	PSI100	Card	Single Flat	0.125	3.20	0.20	0.09	5
PSI4	037103062635	PSI100	Card	Single Flat	0.188	4.80	0.20	0.09	5
PSI5	037103062604	PSI100	Card	Single Flat	0.031	1.00	0.20	0.09	5
PSI6	037103062611	PSI100	Card	Double Flat	0.094	2.40	0.20	0.09	5
PSI7	037103062581	PSI100	Card	Double Flat	0.125	3.20	0.20	0.09	5
PSI8	037103062598	PSI100	Card	Double Flat	0.188	4.80	0.20	0.09	5
PSI9	037103060983	PSI100	Card	Hot Blower	-	-	0.20	0.09	5
PSI10	037103060990	PSI100	Card	Hot Knife	-	-	0.20	0.09	5

Portasol® is a registered trademark of Oglesby and Butler Limited.

Magna-Lite Butane Micro Torch

- Piezo electronic ignition system for reliable ignition every time
- LED light illuminates work in dark conditions
- Adjustable flame height
- Refillable with Weller® WB1 or WB2 filtered butane
- Nozzle cover prevents accidental ignition
- Key ring lanyard
- For heat shrink tubing, fusing rope ends, frozen locks, camping
- Also for labs, and boating



Cat No.	UPC No.	Description	Packed	Pack Wt.		Shelf Pack
				lb	kg	
ML100	037103212559	Magna-Lite Butane Micro Torch	Clamshell	0.64	0.29	8

Magna-Lite Butane Table Top Torch



- Piezo electronic ignition system for reliable ignition every time
- Adjustable flame height
- Up to 60 minutes continuous use controls flame temperature up to 2,400° F
- Child safety lock meets CPSC guidelines
- Refillable with Weller® WB1 or WB2 filtered butane
- For heat shrink tubing, fusing rope ends, frozen locks, camping
- Also for first aid, labs, and boating

Cat No.	UPC No.	Description	Packed	Pack Wt.		Shelf Pack
				lb	kg	
ML200	037103212290	Magna-Lite Butane Table Top Torch	Clamshell	1.8	0.82	4

Premium Butane Fuel



WB1

WB2

- Compatible with Weller® Portasol®, Weller® Pyropen®, and Weller® Magna-Lite tools
- Premium quality butane fuel will not clog
- Printed in English and Spanish with operating instructions on back of can

Cat No.	UPC No.	Brand	Description	Packed	Pack Wt.		Shelf Pack
					lb	kg	
WB1	037103060921	Weller	2.1 oz. Butane Fuel Canister	Box of 12	2.9	1.31	12
WB2	037103126917	Weller	1.0 oz. Butane Fuel Canister	Box of 12	1.1	0.50	12

Portasol® is a registered trademark of Oglesby and Butler Limited.

8 Piece 25 Watt Short Barrel Hobby Iron Kit

- Fine quality consumer mini iron
- Featherweight iron with pencil handle
- Ideal for wood burning, hobbies and crafts
- Also ideal for jewelry, model railroads, and micro electronics
- Develops 900°F/482°C temperature
- Stainless steel barrel and heat and impact resistant handle
- Tips included: Patterb transfer, shading, universal, groove, calligraphy, stencil cutting, hot knife blade and chuck, dot, 3 branding tips
- UL listed



Cat No.	UPC No.	Description	Packed	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
WSB25HK	037103200655	8 Piece 25 Watt Short Barrel Hobby Iron Kit	Clamshell	25	120	2.4	1.09	6

15 Piece 25 Watt Short Barrel Woodburning Kit

- Fine quality consumer mini iron
- Featherweight iron with pencil handle
- Ideal for wood burning, hobbies and crafts
- Also ideal for jewelry, model railroads, and micro electronics
- Develops 900° F/480° C temperature
- Stainless steel barrel, heat and impact resistant handle
- Kit contains 9 woodburning tips, embossing tip, hot knife, and stand
- Includes complete project booklet
- UL and cUL listed



Cat No.	UPC No.	Description	Packed	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
WSB25WB	037103205339	15 Piece 25 Watt Short Barrel Woodburning Kit	Clamshell	25	120	5.25	2.38	6

Marksman® Stained Glass Iron (80 Watts)

- Indicator light allows you to instantly see that the iron is on
- Can tackle the more intricate seams and repair old ones making it ideal for stained glass work
- Simple and safe to use
- Kit contains SP80L iron, MTG20 3/8"/10mm and MTG21 1/4"/6mm pre-tinned iron-plated copper tips and soldering iron rest
- Helpful hints and instructions inside clamshell
- UL Listed. cUL Listed model available
- 7 year warranty



See page 231 for soldering tip listing.

Cat No.	UPC No.	Description	Packed	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
SPG80L	037103169136	Marksman Lighted Stained Glass Soldering Iron	Card	80	120	3.0	1.36	6

Professional Stained Glass Iron (100 Watts)




- Ideal for advanced stained glass work
- Top quality iron for the handyman who wants the best
- Durable iron plated tips
- Temperature control is accomplished through tip selection
- 600°F / 315°C; 700°F / 370°C ; 800°F / 427°C tips available in four different styles: "CT series" tips on page 353
- Kit contains W100PG iron, CT6F7 3/8"/10mm diameter screwdriver tip and soldering iron rest
- Helpful hints and instructions inside clamshell
- UL and cUL Listed

See below for soldering tip listing.

Cat No.	UPC No.	Description	Packed	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
W100PG	037103474261	Heavy-duty Stained Glass Soldering Iron	Clamshell	100	120	4.2	1.90	6

"CT" Series Tips

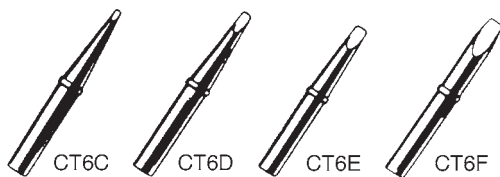

- Tips compatible with W100PG iron
- Precision ground copper tips are plated with iron, nickel and chromium
- Individually bagged for point-of-purchase display

Cat. No.	UPC No.	Packed	Type	Tip Size		Reach		Pack Wt.		Shelf Pack
				Inch	mm	Inch	mm	lb	kg	
CT6C6	037103472847	Bag	Screwdriver - 600°F (315°C)	0.125	3.20	1.370	34.9	0.37	0.16	6
CT6C7	037103472854	Bag	Screwdriver - 700°F (371°C)	0.125	3.20	1.370	34.9	0.37	0.16	6
CT6C8	037103472861	Bag	Screwdriver - 800°F (427°C)	0.125	3.20	1.370	34.9	0.37	0.16	6
CT6D6	037103472878	Bag	Screwdriver - 600°F (315°C)	0.187	4.70	1.370	34.9	0.43	0.19	6
CT6D7	037103472885	Bag	Screwdriver - 700°F (371°C)	0.187	4.70	1.370	34.9	0.43	0.19	6
CT6D8	037103472892	Bag	Screwdriver - 800°F (427°C)	0.187	4.70	1.370	34.9	0.43	0.19	6
CT6E6	037103472908	Bag	Screwdriver - 600°F (315°C)	0.250	6.40	1.370	34.9	0.50	0.22	6
CT6E7	037103472915	Bag	Screwdriver - 700°F (371°C)	0.250	6.40	1.370	34.9	0.50	0.22	6
CT6E8	037103472922	Bag	Screwdriver - 800°F (427°C)	0.250	6.40	1.370	34.9	0.50	0.22	6
CT6F6	037103472939	Bag	Screwdriver - 600°F (315°C)	0.375	9.50	1.370	34.9	0.50	0.22	6
CT6F7	037103472946	Bag	Screwdriver - 700°F (371°C)	0.375	9.50	1.370	34.9	0.50	0.22	6
CT6F8	037103472953	Bag	Screwdriver - 800°F (427°C)	0.375	9.50	1.370	34.9	0.50	0.22	6
CT6F9	037103104427	Bag	Screwdriver - 900°F (482°C)	0.375	9.50	1.370	34.9	0.50	0.22	6
CT6G7	037103479815	Bag	Stained Glass - 700°F (371°C)	-	-	-	-	0.50	0.22	6

Soldering Station for Hobbyist and DIYer

- On/off switch with “power-on” indicator light
- Variable power control produces 5-40 watts
- Quality lightweight pencil iron
- Cushioned foam grip with replaceable heating element
- Ideal for hobbyists, DIYers and students
- Safety guard iron holder
- Natural sponge tip cleaning pad
- ST3 iron-plated copper tip
- UL Listed. cUL Listed model available

See below for soldering tip listing.



Cat No.	UPC No.	Description	Packed	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
WLC100	037103059963	Consumer Soldering Station	Four Color Box	40	120	1.8	0.81	1

Replacement Soldering Iron for WLC100

- Quality lightweight pencil iron
- Cushioned foam grip with replaceable heating element
- Ideal for hobbyists, DIYers and students


See page 245 for soldering tip listing.



Cat No.	UPC No.	Description	Packed	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
SPG40	037103191151	Replacement Soldering Iron for WLC100	Card	40	120	1.86	0.84	6

“ST” Series Tips

- Tips compatible with the SP40L (K) and WLC100 station
- Precision ground copper tips are plated with iron, nickel and chromium
- Tips are individually bagged and packed 10 per box.

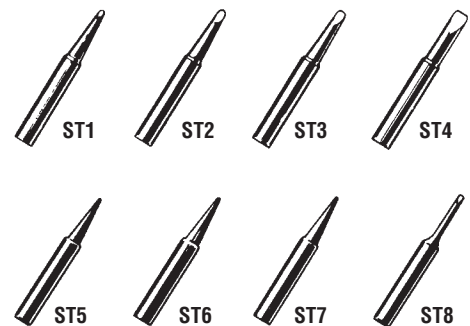

Cat. No.	UPC No.	Use With	Packed	Type	Tip Size		Reach		Pack Wt.		Shelf Pack
					Inch	mm	Inch	mm	lb	kg	
ST1	037103472212	WP25/WP30/WP35	Bag	Screwdriver	0.063	1.60	0.750	19.1	0.25	0.11	10
ST2	037103472434	WP25/WP30/WP35	Bag	Screwdriver	0.093	2.40	0.750	19.1	0.25	0.11	10
ST3	037103472519	WP25/WP30/WP35	Bag	Screwdriver	0.125	3.20	0.750	19.1	0.25	0.11	10
ST4	037103472601	WP25/WP30/WP35	Bag	Screwdriver	0.188	4.70	0.750	19.1	0.25	0.11	10
ST5	037103472809	WP25/WP30/WP35	Bag	Single Flat	0.031	0.80	0.750	19.1	0.25	0.11	10
ST6	037103473189	WP25/WP30/WP35	Bag	Screwdriver	0.031	0.80	0.750	19.1	0.25	0.11	10
ST7	037103473394	WP25/WP30/WP35	Bag	Conical	0.031	0.80	0.750	19.1	0.25	0.11	10
ST8	037103473578	WP25/WP30/WP35	Bag	Narrow Screwdriver	0.062	1.60	0.750	19.1	0.25	0.11	10

Stained Glass Station (80 Watts)




- On/off switch with "power-on" indicator light
- Variable power control produces 5-80 watts
- Quality lightweight stained glass iron
- Cushioned foam grip with replaceable heating element
- Ideal for the hobbyist
- Safety guard iron holder
- Natural sponge tip cleaning pad
- 3/8" replaceable iron-plated tip
- Operates with MTG20, MTG21, MTG22 tips
- UL Listed
- cUL Listed model available

See below for soldering tip listing.

Cat No.	UPC No.	Description	Packed	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
WLC200	037103085030	Stained Glass Soldering Station	Four Color Box	80	120	2.2	0.99	1

Marksman® Series MTG Tips

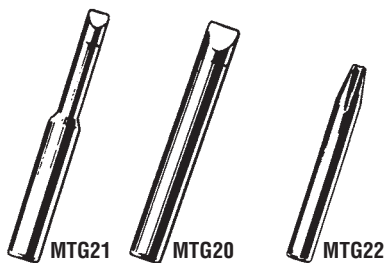

- Marksman® replacement tips
- Nickel-plated copper tips are available in a variety of styles
- MTG series tips are iron-plated for heavy-duty soldering irons
- Hanging bag for point-of-purchase display
- Packed 6 bags per carton

Cat No.	UPC No.	Description	Iron(s)	Packed	Type	Tip Size		Pack Wt.		Shelf Pack
						Inch	mm	lb	kg	
MTG20	037103476593	Tip - 1/Bag	SPG80L/WLC200	Bag	Chisel	0.375	10	0.73	0.33	6
MTG21	037103476609	Tip - 1/Bag	SPG80L/WLC200	Bag	Chisel	0.250	6	0.71	0.32	6
MTG22	037103479822	Tip, Glass Bead - 1/Bag	SPG80L/WLC200	Bag	Cone	0.375	10	0.70	0.32	6

45 Watt Stain Glass Iron



- 45 watt stain glass iron
- Temperature range 1000° F
- Components Supplied: 7760/4033S

Cat No.	UPC No.	Description	Packed	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
1140A	037103042101	Stain Glass Iron	Card	45	120	1.8	0.82	6
4033S	037103031914	Modular Heater with Long Chisel Tip	Box	45	120	1.0	0.45	10

50 Watt Stain Glass Iron

- 50 watt stain glass iron
- Comes with 7760 handle, 37UG heater, PL133 soldering tip
- Working temperature 1000° F

See below for soldering tip listing.



Cat No.	UPC No.	Description	Packed	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
1175	037103042118	Stain Glass Iron	Card	50	120	1.8	0.81	6

0.15" Thread-on Long Taper Chisel Tip

- Solid copper, plated with iron all over
- Nickel and chromium behind the working surface
- Use with heaters 360, 362, 363, 537S, 1237S, 4037S, 37UG
- Designed to provide maximum heat transfer from the heater to the tip



Cat No.	UPC No.	Description	Packed	Temperature	Pack Wt.		Shelf Pack
					lb	kg	
PL133	037103036827	0.15" Thread-on Long Taper Chisel Tip	Card	1000° F	0.15	0.07	10

Heat Gun (1000 Watts)

- Dual temperature, economical heat gun, ideal for most heat gun applications
- Applying heat shrinking products
- Curing epoxy and softening adhesives
- Drying, thawing frozen pipes
- Softening and molding plastics
- Heating liquids and stripping paint
- Dual temperature 1200°F (1000w) and 790°F (400W); 3-way switch: Hi - Off - Low
- 3-wire grounded plug 6' power cord
- Lightweight, 22oz. with cord
- UL and cUL Listed



Catalog No.: 1080
Reducer for concentrating heat



Catalog No.: 1082
Reflector for heat shrink



Catalog No.: 1085
Baffle Kit



Catalog No.: 6959
Adapter for 6966C baffles

Cat No.	UPC No.	Description	Packed	Watts	Volts	Pack Wt.		Shelf Pack
						lb	kg	
1095	037103030740	Dual Temperature Heat Gun	Box	1000	120	1.93	0.87	1
1080	037103030696	Reducer	Card	-	-	0.25	0.11	10
1082	037103030719	Reflector for Heat Shrink Tubing	Card	-	-	0.25	0.11	10
1085	037103030733	Baffle Kit	Card	-	-	0.75	0.34	10
6959	037103034564	Baffle Adapter	Card	-	-	0.70	0.32	20

Cat. No.	Page	Cat. No.	Page	Cat. No.	Page
1080	243	D650	226	SP23LK	229
1082	243	D650PK	226	SP40L	230
1085	243	GT7A	227	SP40LK	230
1095	243	GT7A3	227	SP80L	230
1140A	242	HK11	231	SPG40	241
1175	243	ML100	237	SPG80L	239
4033S	242	ML200	238	ST1	232, 241
6110	227	ML500MP	235	ST2	232, 241
6120	227	ML501	235	ST3	232, 241
6130	227	ML502	235	ST4	232, 241
6140	227	ML503	235	ST5	232, 241
6150	227	MT1	231	ST6	232, 241
6160	227	MT10	231	ST7	232, 241
6959	243	MT2	231	ST8	232, 241
6B	227	MT3	231	TB100PK	232
7135W	227	MT70	231	TB5TK	233
7200PK	225	MTG20	231, 242	W100PG	240
7235	227	MTG21	231, 242	WB1	238
7250N	227	MTG22	231, 242	WB2	238
7250W	227	MTG30	231	WLC100	241
7A	227	MTG40	231	WLC200	242
8125N	227	P2C	236	WPS10	228
8125W	227	P2KC	236	WPS11	228
8200	225	PL133	243	WPS18MP	228
8200PK	225	PPT1	237	WSB25HK	239
BP1	233	PPT2	237	WSB25WB	239
BP10	234	PPT5	237		
BP11	234	PPT6	237		
BP645MP	233	PSI1	237		
BP860MP	234	PSI10	237		
CT6C6	240	PSI100C	236		
CT6C7	240	PSI100K	236		
CT6C8	240	PSI2	237		
CT6D6	240	PSI3	237		
CT6D7	240	PSI4	237		
CT6D8	240	PSI5	237		
CT6E6	240	PSI6	237		
CT6E7	240	PSI7	237		
CT6E8	240	PSI8	237		
CT6F6	240	PSI9	237		
CT6F7	240	RCT	227		
CT6F8	240	SP12	228		
CT6F9	240	SP120	231		
CT6G7	240	SP175	231		
D550	226	SP23L	229		
D550PK	226	SP23LHPK	229		