


NSYCRS50W240V

Climasys Ultra thin resistance heater low
starting current 50W 240V 200x320mm

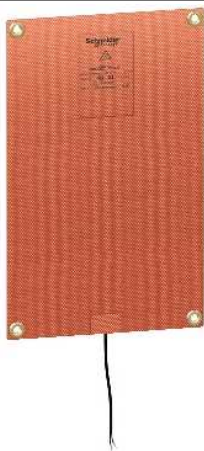

Main

Range	ClimaSys CR
Category	Ultra thin resistance heater
Rated power in W	50 W
Input voltage	240 V AC 50/60 Hz
Electrical connection	Cable length: 2 m

Complementary

Operating position	Horizontal Vertical
Ambient air temperature for operation	-60...70 °C
Temperature setting range	-40...70 °C
Material	Silicone rubber
Height	External : 200 mm
Width	External : 320 mm
Depth	External : 1.6 mm
Device composition	Fixing accessories 4 clip-on nuts 4 Telequick nuts 6 plastic spacers 6 self-adhesive Velcro pads
Condition of use	Electrical protection is needed Heaters must be installed with a thermal controller Air sealed enclosure
Fixing mode	By 4 screws
Mounting support	DIN rail Telequick mounting plate Adhesive Velcro Standard mounting plate

The information provided in this documentation contains general descriptions and/or technical characteristics of the performance of the products contained herein. This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications. It is the duty of any such user or integrator to perform the appropriate and complete risk analysis, evaluation and testing of the products with respect to the relevant specific application or use thereof. Neither Schneider Electric Industries SAS nor any of its affiliates or subsidiaries shall be responsible or liable for misuse of the information contained herein.