


CABLE SPECIFICATION

Model: CBBR4180
Type: Mono Microphone Cable
Specification: (20/0.12MM BC+60/0.10MM BC)X1C
Marketing: MICROPHONE CABLE MONO USA STANDARD

Appearance:

Shape	Color	Length	Package
Circle	Black	100M	Paper Spool

Construction:

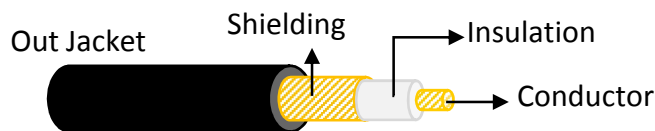

Conductor

Material: Bare Copper (OFC)
Construction: 20 X 0.12 MM
Cross Section: 0.23 MM² (AWG24)

Insulation

Material: Polyvinylchloride (PVC)
Thickness: 0.75 MM
Diameter: 2.2 MM
Color: White

Shielding

Material: Bare Copper (OFC)
Construction: 60X0.10 MM Spiral
coverage: 90%

Out Jacket

Material: Polyvinylchloride (PVC)
Thickness: 1.70 MM
Diameter: 5.80 MM

Operation Temp.: -20⁰C ~ 60⁰C

Approval By:

A handwritten signature in red ink, appearing to be 'Luis J. L.', is written over a horizontal line.