

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: 0439141102
Status: Active
Overview: Mini-Fit Sr.™ Power Connectors
Description: 10.00mm Pitch Mini-Fit Sr.™ Receptacle Housing, Dual Row, 8 Circuits

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Test Summary TS-42815-001 \(PDF\)](#)
[Test Summary TS-42815-004 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
CSA LR19980
UL E29179

General
Product Family Crimp Housings
Series 43914
Application Power, Wire-to-Board, Wire-to-Wire
Overview Mini-Fit Sr.™ Power Connectors
Product Name Mini-Fit Sr.™
UPC 800753933668


Physical
Circuits (maximum) 8
Color - Resin Black
Flammability 94V-0
Gender Female
Glow-Wire Compliant No
Material - Resin Polyester
Net Weight 13.280/g
Number of Rows 2
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 10.00mm
Stackable No
Temperature Range - Operating -40°C to +105°C

Electrical
Current - Maximum per Contact 50.0A

Solder Process Data
Lead-freeProcess Capability N/A

Material Info

Reference - Drawing Numbers
Product Specification RPS-42815-001, RPS-42815-011, RPS-42815-012, RPS-42815-013, RPS-42815-014, RPS-42815-015
Sales Drawing SD-43914-002
Test Summary TS-42815-001, TS-42815-004

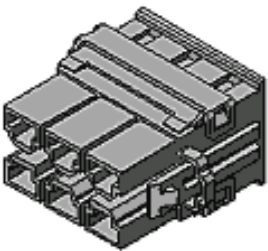

Series image - Reference only

EU ELV
Not Relevant

EU RoHS **China RoHS**
Compliant
REACH SVHC
Contains SVHC(2015 June 15): No
Halogen-Free
Status
Not Low-Halogen
Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS Green Image
ELV Not Relevant

Search Parts in this Series
43914 Series

Mates With
43915 , 43938

Use With
42815 Female Terminal and 43980 TPA Clip

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION