

# C&K PCM Series Ultraminiature Surface Mount Slide Switches



## Features/Benefits

- Ultraminiature surface mount
- Low profile
- SPDT & SP3T models
- RoHS compliant

## Typical Applications

- Computer peripherals & network products
- Telecommunication products
- Test & measurement equipment



Slide

## Specifications

CONTACT RATING: 0.3A @ 6 VDC.  
 MECHANICAL LIFE: 10,000 cycles.  
 CONTACT RESISTANCE: 70 m Ω max.  
 INSULATION RESISTANCE: 100 m Ω min. @ 500V.  
 DIELECTRIC STRENGTH: 500 VAC min.  
 OPERATING TEMPERATURE: -10°C to +85°C.  
 SOLDERABILITY: 255C max. solder temperature.  
 PACKAGING: Tape & reel.

## Materials

CASE: P.P.S.  
 COVER: Stainless steel.  
 SLIDER: Nylon 4/6  
 BRUSH: Copper alloy silver clad.  
 TERMINALS: Copper alloy, silver plated.


**NOTE:** All models RoHS compliant and compatible with all options. For the latest information regarding RoHS compliance, please go to: [www.ittcannon.com/rohs](http://www.ittcannon.com/rohs).

**NOTE:** Specifications and materials listed above are for switches with standard options. For information on specific and custom switches, consult Customer Service Center.

## How To Order

Complete part numbers for PCM Series Ultraminiature Surface Mount Slide Switches are shown below and on page J-44.


### PC MOUNTING

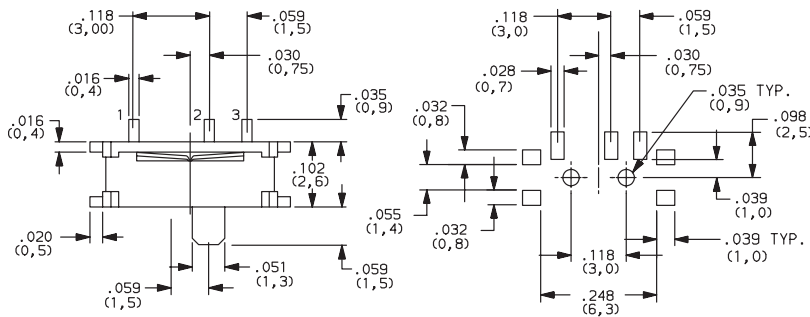

PART NUMBER	SWITCH FUNCTION	
	POS. 1	POS. 2
<b>PCM12SMTR</b>	ON	ON
CONN. TERMINALS	1-2	2-3
SCHEMATIC		
SPDT		





PCM12SMTR  
SPDT

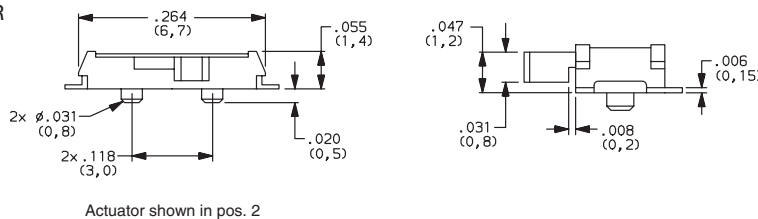

Third Angle Projection  
 Dimensions are shown: Inch (mm)  
 Specifications and dimensions subject to change

# C&K PCM Series Ultraminiature Surface Mount Slide Switches

 
PART NUMBER	SWITCH FUNCTION		
	POS. 1	POS. 2	POS. 3
<b>PCM13SMTR</b>	ON	ON	ON
CONN. TERMINALS	1-3	2-3	3-4
SCHEMATIC			
SP3T			

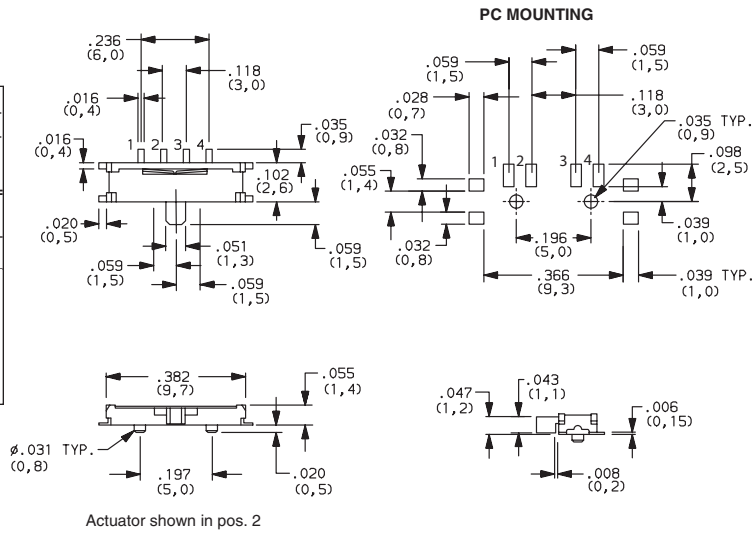



Slide

## TAPE & REEL

For part number PCM12SMTR

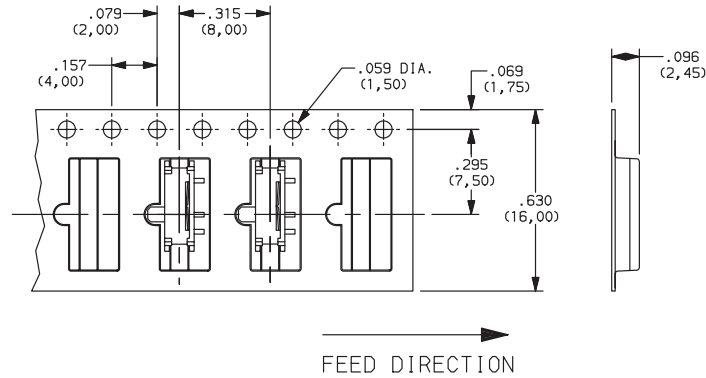

For part number PCM13SMTR

 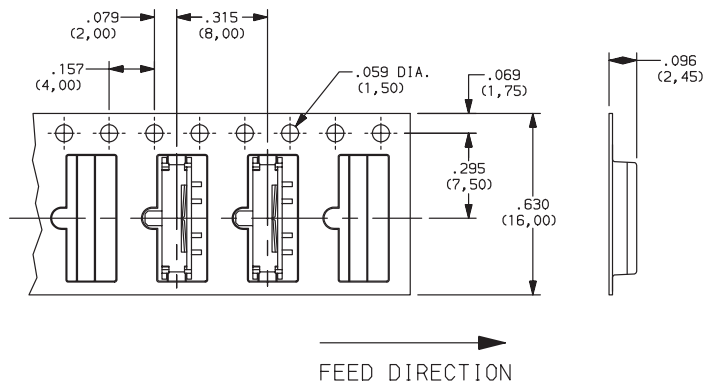

Dimensions are shown: Inch (mm)  
Specifications and dimensions subject to change