


# Electronic systems EL accessories

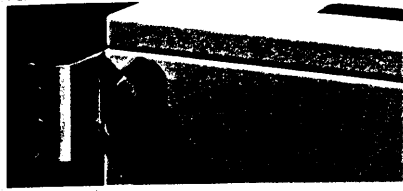

## Wall fixing bracket


For secure attachment of all EL wall-mounted enclosures. The wall fixing brackets, with 10 or 40 mm distance from the wall, also facilitate cable routing behind the enclosure, from the top down to the cable gland plate.

### Material:

Sheet steel, yellow passivated.

Wall distance	Packs of	Model No. SZ
40 mm	1	2503.000
10 mm	1	2508.000

898-302.

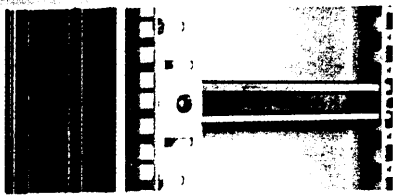

## C rails


For EL 2243.600 – EL 2271.600 and centre parts EL 2230.400 – EL 2230.600  
For infinite depth-variability of the mounting angles, including fixing material.

### Material:

Sheet steel, yellow passivated.

For centre part depth	Packs of	Model No. EL
216 mm	4	2238.000
316 mm	4	2239.000
416 mm	4	2237.000

German patent no. 39 30 161

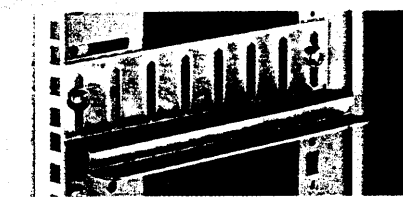

## Slide rails

For EL 2243.600 – EL 2271.600 and centre parts EL 2230.400 – EL 2230.600  
For the installation of heavy slide-in equipment.

### Material:

Sheet steel, yellow passivated.

For centre part depth	Packs of	Model No. EL
216 mm	10	2240.000
316 mm	10	2250.000
416 mm	10	2260.000



## Ergoform Mini

For EL 2243.600 – EL 2271.600 and glazed door EL 2230.010 – EL 2230.070  
Prepared for 40 mm semi-cylinders or for SZ 2467.000 and SZ 2469.000 lock inserts.

Packs of	Model No. EL
1	2242.000



 
## Lock inserts

Prepared for installation in Ergoform Mini.  
Model No. EL 2242.000.

### Note:

Lock inserts, version A in exchange for double-bit insert – see page 697.

Lock system	Packs of	Model No. SZ
No. 3524 E	1	2467.000
Push-button with no. 2123	1	2469.000



## Mounting plate

Mounting plate for retrofitting in the base box.

**Supply includes:**  
Mounting plate

**Material:**  
2.75 mm sheet steel

**Surface finish:**  
Zinc-plated

U	Height mm	Model No. EL
3	165	2236.710
6	299	2236.720
9	432	2236.730
12	565	2236.740
15	699	2236.750
18	832	2236.760
21	965	2236.770

