

Data Sheet
3-668-15 EUROLINE



Part Number 3-668-15

Special pliers made from high grade special steel for extremely high requirements;
by precision inductive hardness process blades achieve up to 65 HRC

Box joint

precise jaw adjustment without backlash

fine polished and bright burnished surface

Double leaf spring from stainless steel

Ergonomically formed bicoloured hand guard from dissipative anti-slide material

The pliers of this programme have been tested with good results by several test laboratories adequate to DIN EN 61340-5-1, DIN 61340-2-1, DIN 61340-2-3 for work in ESD protected areas.



Description: Side cutters EUROLINE
with rounded head


Characteristics:

Blade Finish Semi Flush



Cutting capacity soft wire	Ø 2.0 mm
Cutting capacity medium wire	Ø 1.5 mm
Cutting capacity hard wire	Ø 0.7 mm

A - Head width	14 mm
B - Head thickness	9 mm
C - Blade / jaw length	17 mm

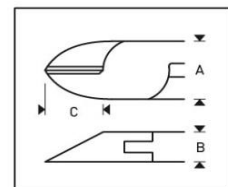

Length 135 mm

Weight 110 g

Customs Tariff No. 82032000



EAN-No.

Link to catalogue page www.bernstein-werkzeuge.de/Katalogseiten/EUROLINE-Conductive_English.pdf

Link to image <http://www.bernstein-werkzeuge.de/Artikelbilder/03/3-668-15.jpg>

Image file 3-668-15.jpg

Keywords pliers; electronic pliers; side cutters